

Mini (7/8) 3 pole, Male (Ext.) 90°/Female 90° ,
PUR, UL/CSA, 3x16AWG, black, 1.5m

Male 90° – female 90°
7/8" – 7/8", 3-pole
Power cable
USA
Further cable lengths on request.
Plastic housings with good resistance against chemicals and oils.
The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)

Illustration



Product may differ from Image

Approvals



* only for products with UL/CSA approved cable

Form

Form A3A31

General data

Temperature range -25...+80 °C, depending on cable quality


Cables

Cable number	UMB
No./diameter of wires	3× 1.5 mm²
Wire isolation	TPM (br, bl, gnye)
C-track properties	5 Mio.
Jacket Color	black
Material (jacket)	PUR (UL/CSA)
Outer Ø	7.4 mm ±5%
Bend radius (fixed)	7.5× outer Ø
Bend radius (moving)	10× outer Ø
Temperature range (fixed)	-40...+80 °C
Temperature range (mobile)	-20...+80 °C

Technical Data

Operating voltage	max. 600 V AC/DC
Operating current per contact	max. 12 A
Locking of ports	Screw thread 7/8" (recommended torque 1.5 Nm) self-securing
Protection	IP68 inserted and tightened (EN 60529)
Compression gland	7/8" (SW24)

Locking material	Zinc die casting, matte nickel plated
Material	PUR
Commercial data	
country of origin	DE
customs tariff number	85444290
EAN	4048879637053
eClass	27279218
Packaging unit	1
Sketch	

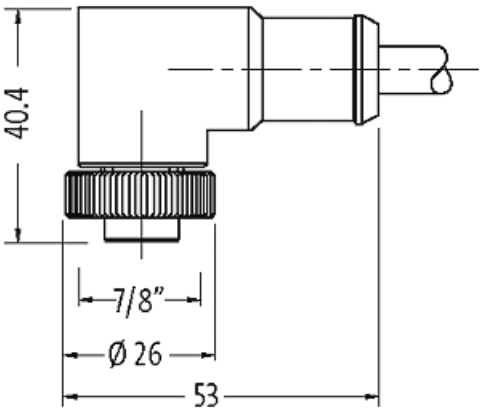

Product may differ from Image