



Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 11/20

Rated surge voltage	4.0 kV
Operating current per contact	max. 9 A
No. of poles	5
LED display	no
Locking of ports	Screw thread 7/8" (recommended torque 1.5 Nm) self-securing
Compression gland	7/8" (SW24)
Protection	IP68 inserted and tightened (EN 60529)
Locking material	Zinc die casting, matte nickel plated
Material	PUR


Commercial data

country of origin	DE
customs tariff number	85444290
EAN	4048879640718
eClass	27279218
Packaging unit	1

Sketch

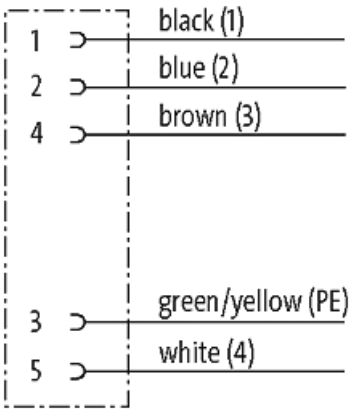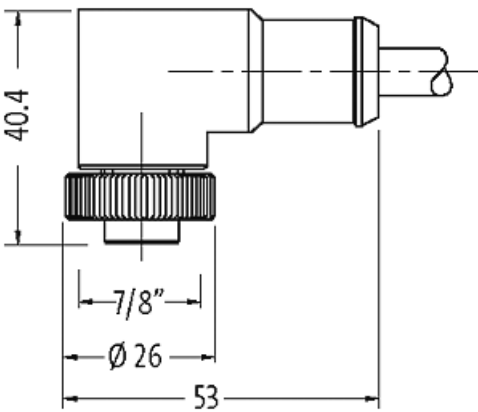

Female

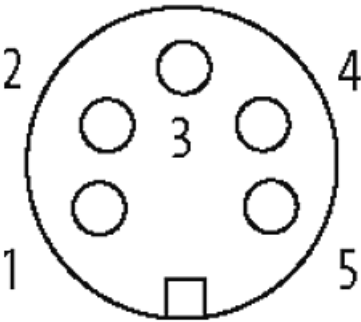

Product may differ from Image