


Mini (7/8) 5 pole, Male (Ext.) Straight/Female Straight,
PVC, STOOW, 5x16AWG, yellow, 1.5m

Male straight – female straight
7/8" – 7/8", 5-pole
Power cable
USA
Further cable lengths on request.
Plastic housings with good resistance against chemicals and oils.
The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)

Illustration

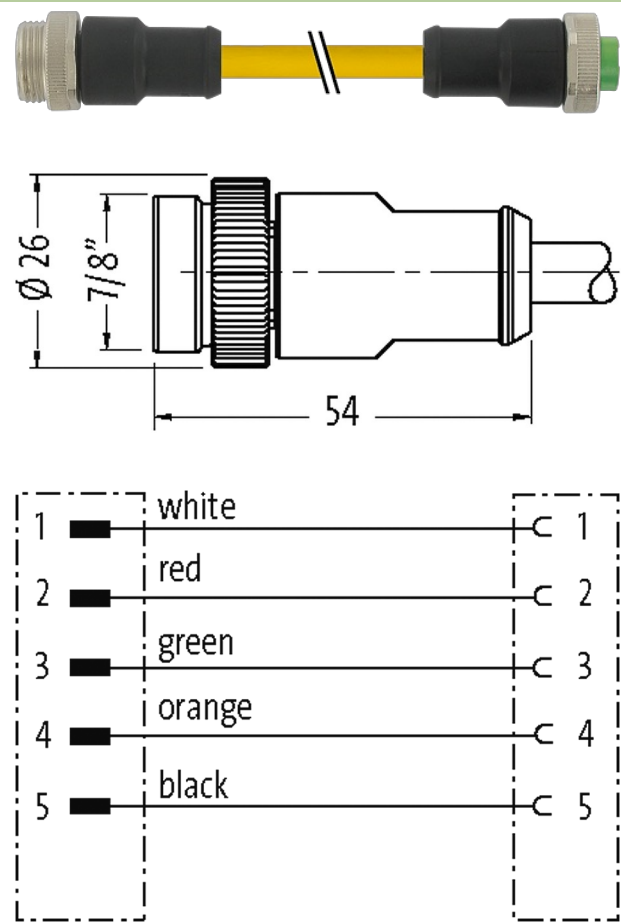

Product may differ from Image

Approvals



* only for products with UL/CSA approved cable

Form

Form A5A01

General data


Temperature range -25...+80 °C, depending on cable quality

Cables	
Cable number	UBD
No./diameter of wires	5× 1.5 mm²
Construction (core)	approx. 3.1 mm
Wire isolation	PVC (bk, or, gn, rd, wh)
Jacket Color	yellow
Material (jacket)	PVC (UL/CSA)
Outer Ø	12.7 mm ±5%
Bend radius (fixed)	10× outer Ø
Bend radius (moving)	15× outer Ø
Temperature range (fixed)	-50...+105 °C
Temperature range (mobile)	-20...+90 °C

Technical Data	
Operating voltage	max. 600 V AC/DC
Operating current per contact	max. 9 A
Locking of ports	Screw thread 7/8" (recommended torque 1.5 Nm) self-securing
Compression gland	7/8" (SW24)
Protection	IP68 inserted and tightened (EN 60529)
Locking material	Zinc die casting, matte nickel plated
Material	PUR

Commercial data	
country of origin	DE
customs tariff number	85444290
EAN	4048879632706
eClass	27279218
Packaging unit	1

Sketch

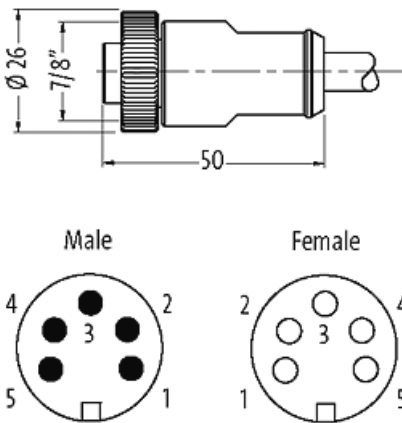

Product may differ from Image