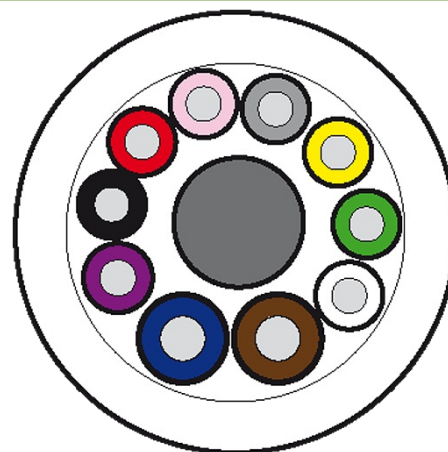


50M MAIN CABLE PUR/PVC-OB 8X0,34+2X0,75

for 4-way distribution boxes M8

PUR/PVC

8× 0.34 + 2× 0.75 mm²[Link to Product](#)**Illustration**

Product may differ from Image

Cables

Cable number	358
No./diameter of wires	8× 0.34 + 2× 0.75 mm ²
Wire isolation	PVC
C-track properties	1.5 Mio.
Jacket Color	gray
Material (jacket)	PUR/PVC
Outer Ø	8.6 mm ±5%
Bend radius (fixed)	10× outer Ø
Bend radius (moving)	12× outer Ø
Temperature range (fixed)	-30...+70 °C
Temperature range (mobile)	-5...+60 °C
Color (jacket)	gray

Commercial data

country of origin	IT
customs tariff number	85444995
EAN	4048879299985
eClass	27062011
Packaging unit	1