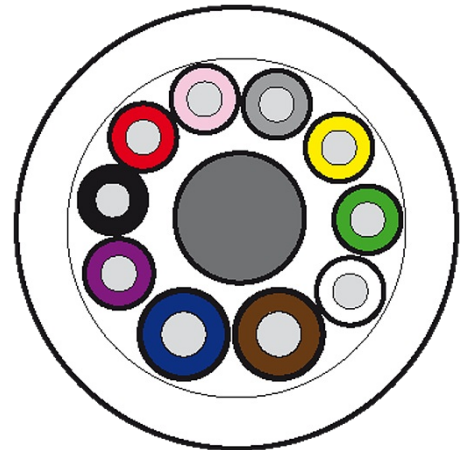


50M MAIN CABLE PUR-OB 8*0,34+2*0,75

4-way distribution boxes M8
8 × 0.34 + 2 × 0.75 mm²

[Link to Product](#)**Illustration**

Product may differ from Image

Cables

Cable number	360
No./diameter of wires	8 × 0.34 + 2 × 0.75 mm ²
Wire isolation	TPE (brgn, whgn, rdbl, grpk, gr, ye, gn, wh+br, bl)
C-track properties	5 Mio.
Jacket Color	gray
Material (jacket)	PUR (UL/CSA)
Outer Ø	9.2 mm ±5%
Bend radius (fixed)	5 × outer Ø
Bend radius (moving)	10 × outer Ø
Temperature range (fixed)	-40...+80 °C
Temperature range (mobile)	-5...+60 °C
Color (jacket)	gray

Commercial data

country of origin	IT
customs tariff number	85444995
EAN	4048879057240
eClass	27062011
Packaging unit	1