


50M MAIN CABLE PUR-JB 8*0,34+3*0,75

4-way distribution boxes M12, shielded
8× 0.34 + 3× 0.75 mm²

[Link to Product](#)

Illustration

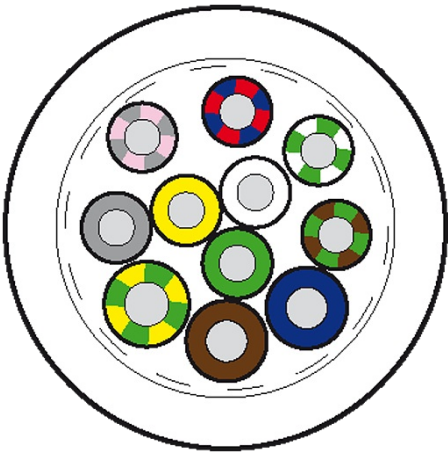

Product may differ from Image

Cables	
Cable number	373
No./diameter of wires	8× 0.34 + 3× 0.75 mm²
Wire isolation	TPE (grpk, wh, rdbl, gn, whgn, ye, brgn, gr, br, bl, gnye)
C-track properties	5 Mio.
Jacket Color	gray
Material (jacket)	PUR (UL/CSA)
Outer Ø	9.3 mm ±5%
Bend radius (fixed)	10× outer Ø
Bend radius (moving)	12× outer Ø
Temperature range (fixed)	-40...+90 °C
Temperature range (mobile)	-40...+90 °C
Shield	yes
Color (jacket)	gray
Commercial data	
country of origin	IT
customs tariff number	85444995
EAN	4048879057202
eClass	27062011
Packaging unit	1