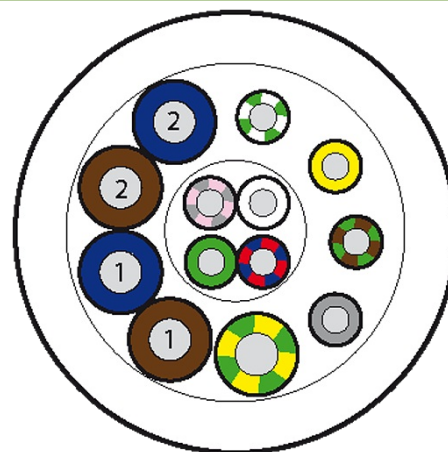


50M MAIN CABLE PUR/PVC-JB 8*0,34+5*0,75

4-way distribution boxes M12, potentially separated

PUR/PVC

8× 0.34 + 5× 0.75 mm²[Link to Product](#)**Illustration**

Product may differ from Image

Cables

Cable number	374
No./diameter of wires	8× 0.34 + 5× 0.75 mm ²
Wire isolation	PVC
C-track properties	1.5 Mio.
Jacket Color	gray
Material (jacket)	PUR/PVC
Outer Ø	9.2 mm ±5%
Bend radius (fixed)	10× outer Ø
Bend radius (moving)	12× outer Ø
Temperature range (fixed)	-30...+80 °C
Temperature range (mobile)	-30...+80 °C
Color (jacket)	gray

Commercial data

country of origin	IT
customs tariff number	85444995
EAN	4048879057196
eClass	27062011
Packaging unit	1