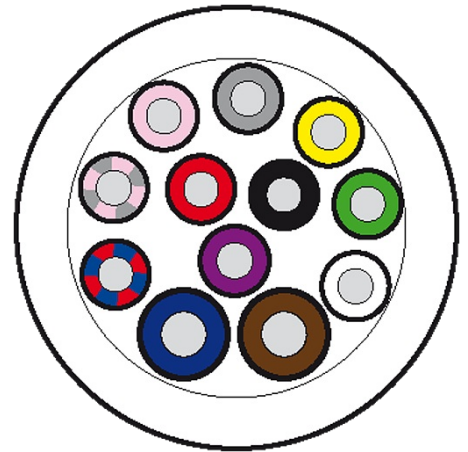


50M MAIN CABLE PUR-OB 10*0,34+2*0,75

10-way distribution boxes M8
 10× 0.34 + 2× 0.75 mm²

[Link to Product](#)**Illustration**

Product may differ from Image

Cables

Cable number	384
No./diameter of wires	10× 0.34 + 2× 0.75 mm ²
C-track properties	5 Mio.
Jacket Color	gray
Material (jacket)	PUR (UL/CSA)
Outer Ø	9.3 mm ±5%
Bend radius (fixed)	5× outer Ø
Bend radius (moving)	10× outer Ø
Temperature range (fixed)	-40...+80 °C
Temperature range (mobile)	-5...+60 °C
Color (jacket)	gray
Approval (cable)	UL (AWM-Style 20233), CSA

Commercial data

country of origin	IT
customs tariff number	85444995
EAN	4048879057189
eClass	27062011
Packaging unit	1