


50M MAIN CABLE PUR/PVC 10X0,34+2X0,75

for 10-way distribution boxes M8
PUR/PVC
10× 0.34 + 2× 0.75 mm²

[Link to Product](#)

Illustration

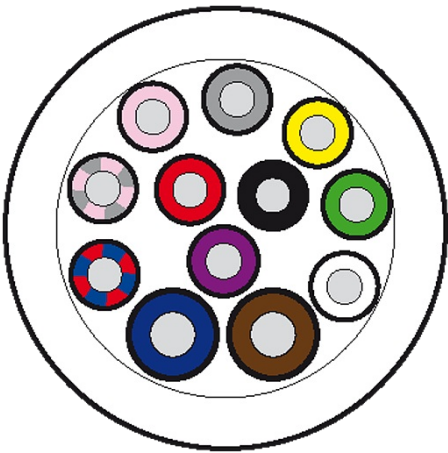

Product may differ from Image

Cables	
Cable number	385
No./diameter of wires	10× 0.34 + 2× 0.75 mm²
Wire isolation	PVC (br, bl, wh, gn, pk, ye, bk, gr, rd, vi, grpk, rdbl)
C-track properties	2 Mio.
Jacket Color	gray
Material (jacket)	PUR/PVC
Outer Ø	8.3 mm ±5%
Bend radius (fixed)	5× outer Ø
Bend radius (moving)	10× outer Ø
Temperature range (fixed)	-30...+80 °C
Temperature range (mobile)	-5...+60 °C
Color (jacket)	gray
Commercial data	
country of origin	IT
customs tariff number	85444995
EAN	4048879057172
eClass	27062011
Packaging unit	1