


50M MAIN CABLE PUR/PVC-JB 12*0,34+3*0,75

6-way distribution boxes M12
PUR/PVC
12× 0.34 + 3× 0.75 mm²

[Link to Product](#)

Illustration

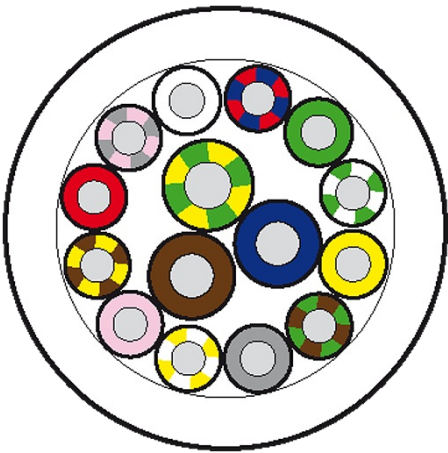

Product may differ from Image

Cables	
Cable number	388
No./diameter of wires	12× 0.34 + 3× 0.75 mm²
Wire isolation	PVC (yebr, rd, grpk, wh, rdbl, gn, whgn, ye, brgn, gr, whye, pk, br, gnye, bl)
C-track properties	2 Mio.
Jacket Color	gray
Material (jacket)	PUR/PVC
Outer Ø	9.8 mm ±5%
Bend radius (fixed)	10× outer Ø
Bend radius (moving)	12× outer Ø
Temperature range (fixed)	-30...+80 °C
Temperature range (mobile)	-5...+70 °C
Color (jacket)	gray
Commercial data	
country of origin	IT
customs tariff number	85444995
EAN	4048879057165
eClass	27062011
Packaging unit	1