


50M MAIN CABLE PUR/PVC-JB 16*0,34+5*0,75

8-way distribution boxes M12
PUR/PVC
16× 0.34 + 5× 0.75 mm²

Link to Product

Illustration

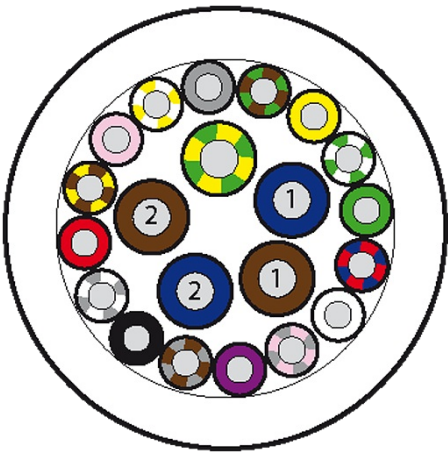

Product may differ from Image

Cables	
Cable number	404
No./diameter of wires	16× 0.34 + 5× 0.75 mm²
Wire isolation	PVC
C-track properties	1.5 Mio.
Jacket Color	gray
Material (jacket)	PUR/PVC
Material (wire)	Cu wire, bare
Resistor (core)	max. 57 Ω/km (0.34 mm²), max. 26 Ω/km (0.75 mm²); (20 °C)
Outer Ø	12.5 mm ±5%
Bend radius (fixed)	10× outer Ø
Bend radius (moving)	12× outer Ø
Temperature range (fixed)	-30...+80 °C
Temperature range (mobile)	-30...+80 °C

Commercial data	
country of origin	IT
customs tariff number	85444995
EAN	4048879057097
eClass	27062011
Packaging unit	1