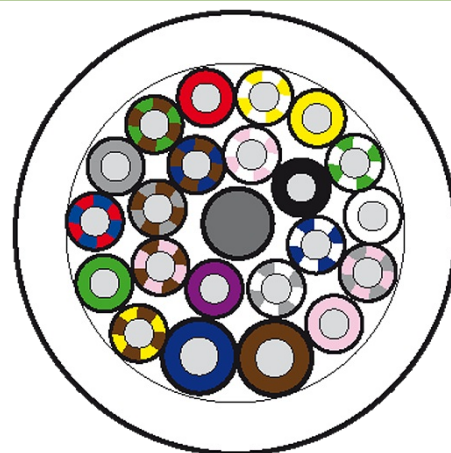


50M MAIN CABLE PUR-OB 20*0,34+2*0,75

for 10-way distribution boxes M8
 $20 \times 0.34 + 2 \times 0.75 \text{ mm}^2$

[Link to Product](#)**Illustration**

Product may differ from Image

Cables

Cable number	411
No./diameter of wires	$20 \times 0.34 + 2 \times 0.75 \text{ mm}^2$
C-track properties	5 Mio.
Jacket Color	gray
Material (jacket)	PUR (UL/CSA)
Outer Ø	11.3 mm $\pm 5\%$
Bend radius (fixed)	5× outer Ø
Bend radius (moving)	10× outer Ø
Temperature range (fixed)	-40...+80 °C
Temperature range (mobile)	-5...+60 °C
Approval (cable)	UL (AWM-Style 20233), CSA

Commercial data

country of origin	IT
customs tariff number	85444995
EAN	4048879057080
eClass	27062011
Packaging unit	1