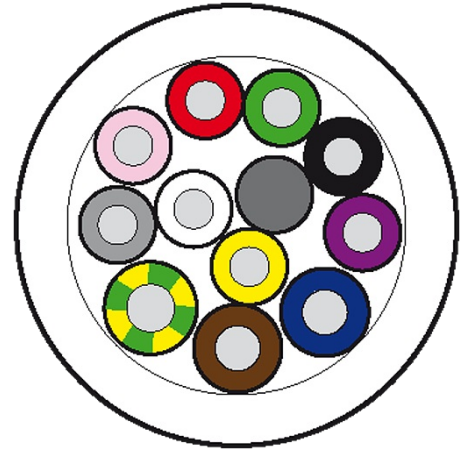


**50M MAIN CABLE PUR 8X0,5+3X1,0**

8-way distribution boxes M12  
PUR (UL/CSA)  
8× 0.5 + 3× 1.0 mm<sup>2</sup>

[Link to Product](#)**Illustration**

Product may differ from Image

**Cables**

Cable number	447
No./diameter of wires	8× 0.5 + 3× 1.0 mm <sup>2</sup>
C-track properties	5 Mio.
Jacket Color	gray
Material (jacket)	PUR (UL/CSA)
Outer Ø	9.4 mm ±5%
Bend radius (fixed)	5× outer Ø
Bend radius (moving)	10× outer Ø
Temperature range (fixed)	-40...+80 °C
Temperature range (mobile)	-5...+80 °C

**Commercial data**

country of origin	IT
customs tariff number	85444995
EAN	4048879377492
eClass	27062011
Packaging unit	1