

MVP-METALL, 8XM12, 5POLE, M23 19POL. CON.

Connector exit frontside


8-way, 5-pole

M23 plug connection, 19-pole


with LED for digital PNP-signals 24 V DC

Replaces identical product (Art.No. 27535)


Connection cables are in the online shop under "Connection Technology".

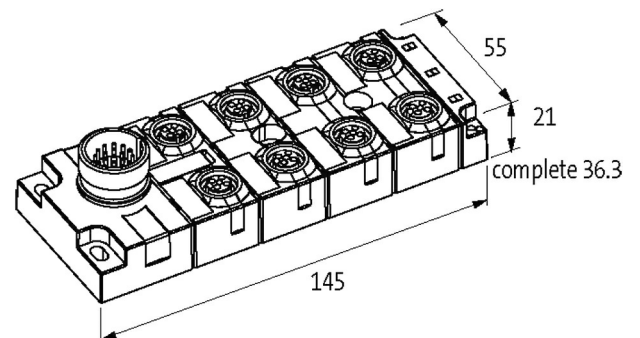[Link to Product](#)**Illustration**

 M12-Females 5-pole




M23-Plug 19-pole

 




M23-Plug

19-pole

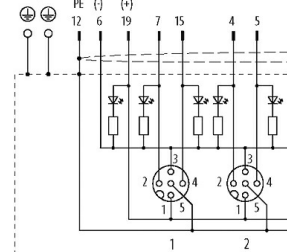


for 2 signals per port

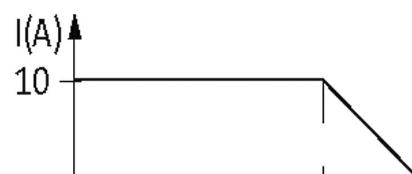

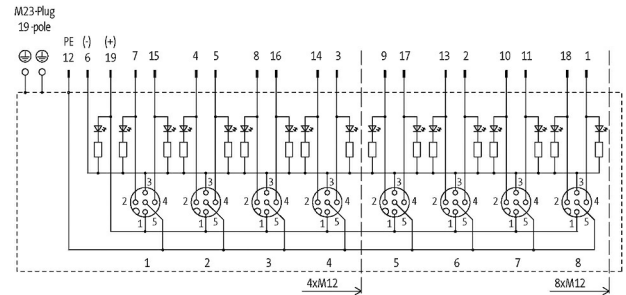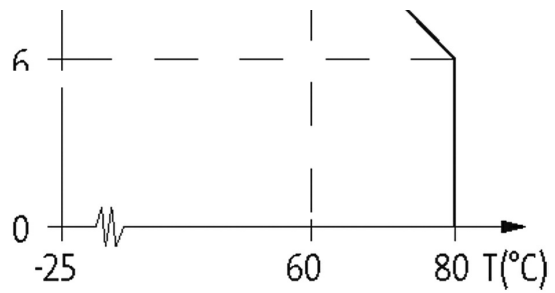

Product may differ from Image

Approvals

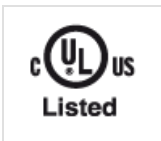

Contact Layout

PIN 1	(+)
PIN 2	(NC)/(S2)
PIN 3	(-)
PIN 4	(NO)/(S1)
PIN 5	(Earth)
Shield	via M12 outer thread and M23 outer thread
LED display	LED (green): Power / LED (yellow): (S1/S2)

General data

Temperature range	-25...+90 °C
-------------------	--------------

Technical Data

Operating voltage	24 V DC
Operating current per contact	max. 4 A
Total current	max. 7.5 A
Protection	IP65, IP67, IP68
Housing	Zinc die casting, matte nickel plated

Commercial data

country of origin	CZ
customs tariff number	85369010
EAN	4048879352888
eClass	27279219
Packaging unit	1