

**EXACT8, 10XM8, 3 POLE PRE-WIRED CABLE**

5.0m PUR/PVC 10\*0,34+2\*0,75

10-way, 3-pole

Further cable lengths on request.

Plastic housings with good resistance against chemicals and oils.


The resistance to aggressive media should be individually tested for your application. Further details on request.

PUR/PVC



5.0 m

[Link to Product](#)

**Illustration**

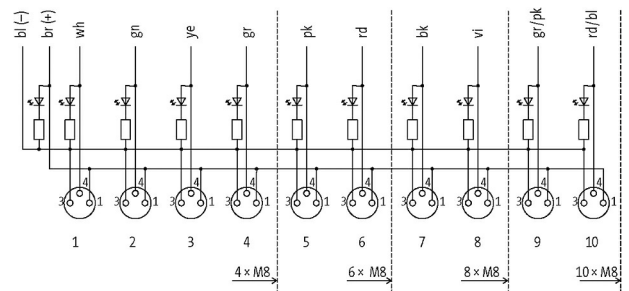

M8-Females 3-pole

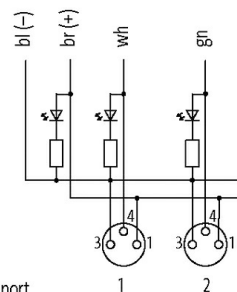 

for 1 signal per port

Product may differ from Image

**Approvals**



**Contact Layout**

PIN 1	(+)
PIN 3	(-)
PIN 4	(NO)/(S1)
LED display	LED (green): Power / LED (yellow): (S1)

**General data**

Temperature range	-20...+80 °C, depending on cable quality
-------------------	--

**Cables**


Cable number	385
No./diameter of wires	10× 0.34 + 2× 0.75 mm <sup>2</sup>
Wire isolation	PVC (br, bl, wh, gn, pk, ye, bk, gr, rd, vi, grpk, rdbl)
C-track properties	2 Mio.
Jacket Color	gray
Material (jacket)	PUR/PVC
Outer Ø	8.3 mm ±5%
Bend radius (fixed)	5× outer Ø
Bend radius (moving)	10× outer Ø
Temperature range (fixed)	-30...+80 °C
Temperature range (mobile)	-5...+60 °C
Color (jacket)	gray

**Technical Data**

Operating voltage	24 V DC
Operating current per contact	max. 2 A
Total current	max. 8 A
Signal per port	1 - (31-32)
Protection	IP65/IP67
Housing	Plastic, flame retardant
Locking of ports	Screw thread (M8×1 mm)

**Commercial data**

country of origin	DE
customs tariff number	85444290
EAN	4048879056953
eClass	27279219
Packaging unit	1

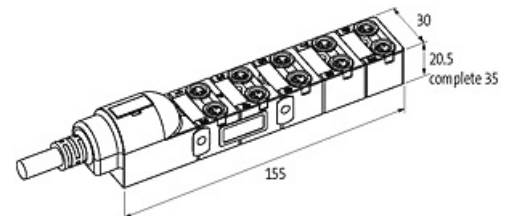**Sketch**

Product may differ from Image