

EXACT12, 4XM12, 5 POLE, M23 12 POLE CON.

Without con. cable

4-way, 5-pole

M23 plug connection

12-pole used

with LED for digital PNP-signals 24 V DC

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)

Illustration

LED display LED (green): Power / LED (yellow): (S1) / LED (white): Signal (S2)

General data

Temperature range -20...+75 °C

Technical Data

Operating voltage 24 V DC

Operating current per contact max. 4 A

Total current max. 8 A

Protection IP65/IP67

Housing Plastic, flame retardant

Commercial data

country of origin DE


customs tariff number 85369010

EAN 4048879055659

eClass 27279219

Packaging unit 1

Sketch

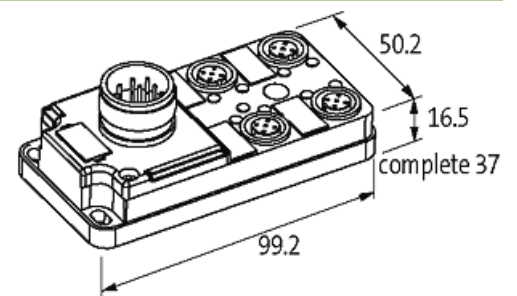

Product may differ from Image