

**EXACT8, 6XM8, 3 POLE**

Connector M12 8-pole

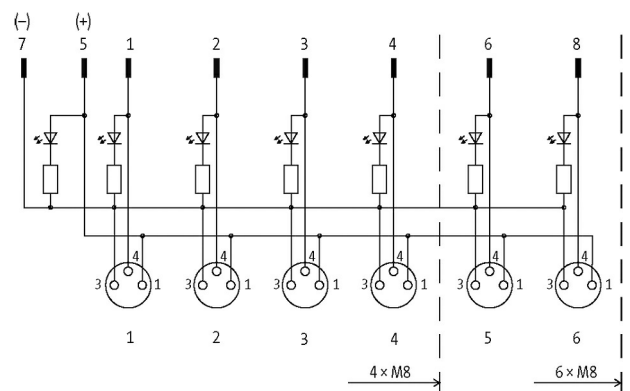
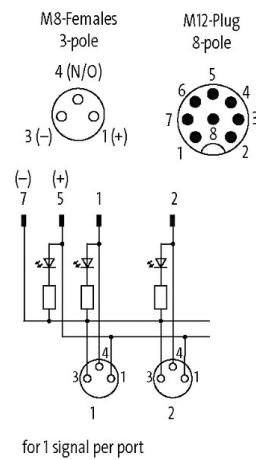
6-way, 3-pole

M12 (8-pole)

Inline face or side mounting

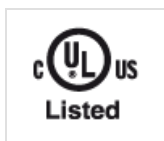
Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Product may differ from Image

**Approvals**



#### Contact Layout

PIN 1	(+)
PIN 3	(-)
PIN 4	(NO)/(S1)
LED display	LED (green): Power / LED (yellow): (S1)

#### General data

Temperature range	-20...+70 °C, depending on cable quality
-------------------	--

#### Technical Data

Operating voltage	24 V DC
Operating current per contact	max. 2 A
Protection	IP65/IP67
Housing	Plastic, flame retardant

#### Commercial data

country of origin	DE
customs tariff number	85369010
EAN	4048879055017
eClass	27143423
Packaging unit	1