

**EXACT8, 8XM8, 3 POLE MOULDED CABLE**

5.0m PUR 8x0,34+2x0,75 NPN-LED's

8-way, 3-pole

for NPN signals 24 V DC


Further cable lengths on request.

Plastic housings with good resistance against chemicals and oils.



The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)

**Illustration**

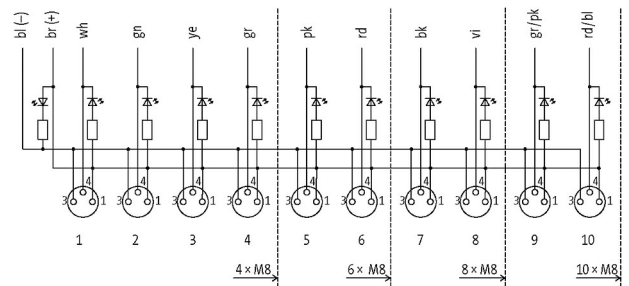

M8-Females 3-pole

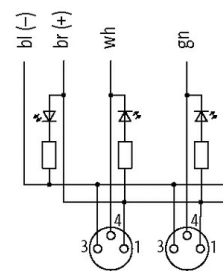 

for 1 signal per port

Product may differ from Image

**Approvals**



**Contact Layout**

PIN 1	(+)
PIN 3	(-)
PIN 4	(NO)/(S1)
LED display	LED (green): Power / LED (yellow): (S1)

#### General data

Temperature range	-20...+80 °C, depending on cable quality
-------------------	--

#### Cables

Cable number	359
No./diameter of wires	8 × 0.34 + 2 × 0.75 mm <sup>2</sup>
Wire isolation	TPE (vi, bk, rd, pk, gr, ye, gn, wh+br, bl)
C-track properties	5 Mio.
Jacket Color	gray
Material (jacket)	PUR (UL/CSA)
Outer Ø	9.2 mm ±5%
Bend radius (fixed)	5 × outer Ø
Bend radius (moving)	10 × outer Ø
Temperature range (fixed)	-40...+80 °C
Temperature range (mobile)	-5...+60 °C
Color (jacket)	gray


#### Technical Data

Operating voltage	24 V DC
Operating current per contact	max. 2 A
Total current	max. 8 A
Signal per port	1 - (31-32)
Protection	IP65/IP67
Housing	Plastic, flame retardant
Locking of ports	Screw thread (M8×1 mm)

#### Commercial data

country of origin	DE
customs tariff number	85444290
EAN	4048879054706
eClass	27143423
Packaging unit	1

#### Sketch

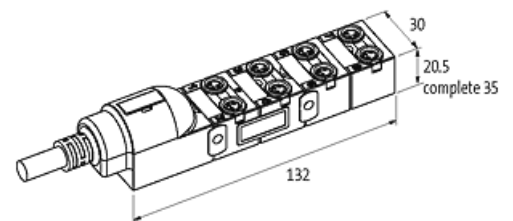

Product may differ from Image