

**EXACT8, 8XM8, 4 POLE BASIC HOUSING**

Without homerun-cable

8-way, 4-pole

Inline face or side mounting

Plastic housings with good resistance against chemicals and oils.



 
The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)

**Illustration**




M8-Females 4-pole

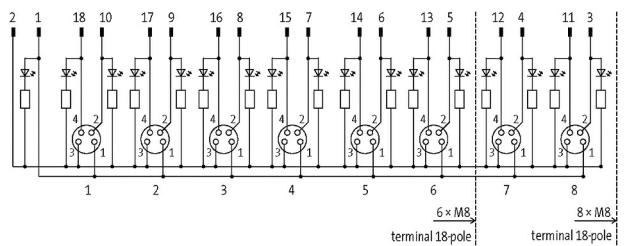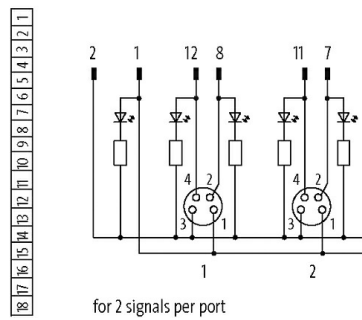

Product may differ from Image

**Approvals**

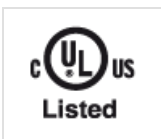

**Contact Layout**

PIN 1	(+)
PIN 2	(NC)/(S2)

PIN 3	(-)
PIN 4	(NO)/(S1)
LED display	LED (green): Power / LED (yellow): (S1) / LED (white): Signal (S2)

**General data**

Temperature range	-20...+70 °C, depending on cable quality
-------------------	------------------------------------------

**Technical Data**

Operating voltage	24 V DC
Operating current per contact	max. 2 A
Total current	max. 8 A
Protection	IP65/IP67

**Commercial data**

country of origin	DE
customs tariff number	85369010
EAN	4048879054508
eClass	27143423
Packaging unit	1