

**EXACT12, 8XM12, 4 POLE, CON. M23 12 POLE**

Without con. cable

8-way, 4-pole

M23 plug connection

12-pole used

with LED for digital PNP-signals 24 V DC

Plastic housings with good resistance against chemicals and oils.

 
The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)



Illustration





M12-Females 4-pole



M23-Plug  
12-pole

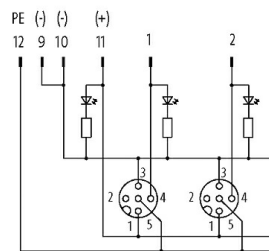 


for 1 signal per port

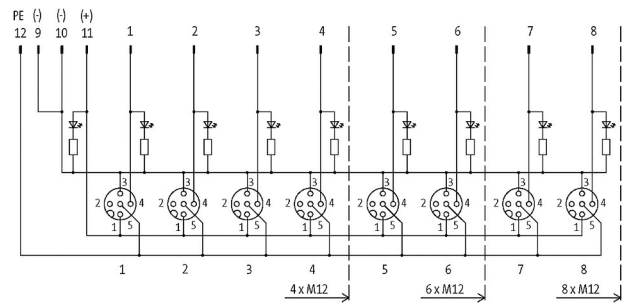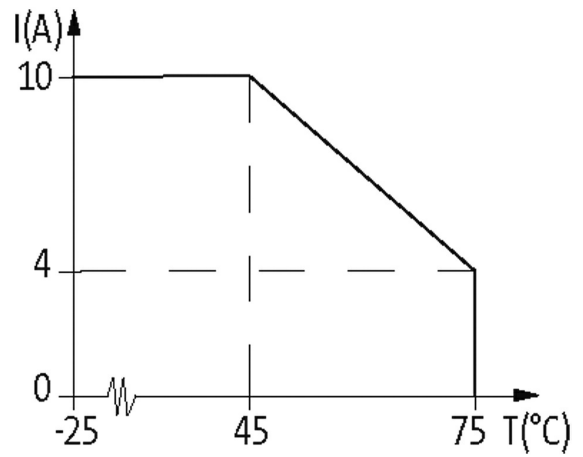

Product may differ from Image

**Approvals**

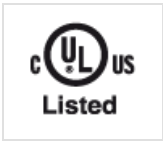

#### Contact Layout

PIN 1	(+)
PIN 3	(-)
PIN 4	(NO)/(S1)
PIN 5	(Earth)
LED display	LED (green): Power / LED (yellow): (S1)

#### General data

Temperature range	-20...+75 °C
-------------------	--------------


#### Technical Data

Operating voltage	24 V DC
Operating current per contact	max. 4 A
Total current	max. 8 A
Protection	IP65/IP67
Housing	Plastic, flame retardant

#### Commercial data

country of origin	DE
customs tariff number	85369010
EAN	4048879054188
eClass	27143423
Packaging unit	1

#### Sketch

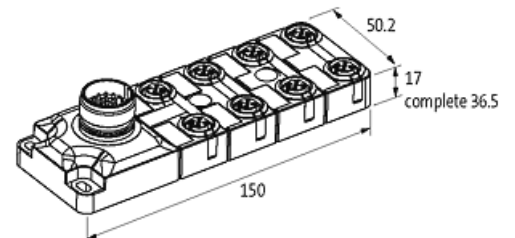

Product may differ from Image