

**EXACT12, 8XM12, 5-POLE, BASIC HOUSING, W.O. LED'S**

Without homerun-cable

8-way, 5-pole

without LED, up to 125 V AC/DC

Screw plug-in terminals



 
Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

Further cable lengths on request.

**[Link to Product](#)****Illustration**

M12-Females 5-pole

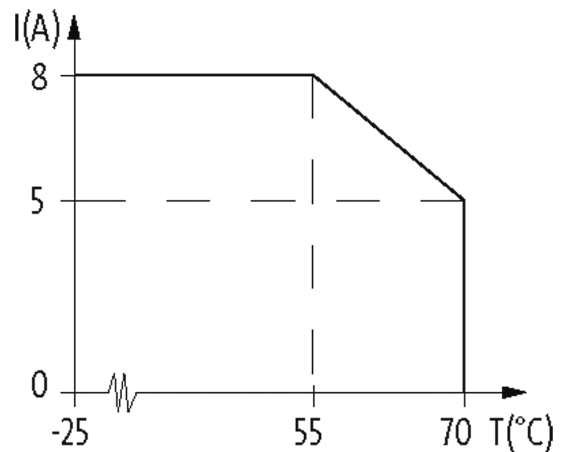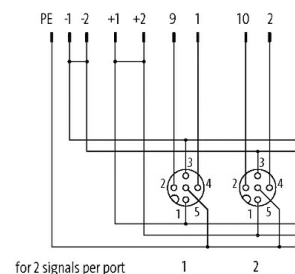

Product may differ from Image

### Approvals



### Contact Layout

PIN 1	(+)
PIN 2	(NC)/(S2)
PIN 3	(-)
PIN 4	(NO)/(S1)

### General data

Temperature range	-20...+70 °C
-------------------	--------------


### Technical Data

Operating voltage	125 V AC/DC
Operating current per contact	max. 4 A
Total current	max. 8 A
Protection	IP65/IP67
Housing	Plastic, flame retardant

### Commercial data

country of origin	DE
customs tariff number	85369010
EAN	4048879054041
eClass	27143423
Packaging unit	1

### Sketch

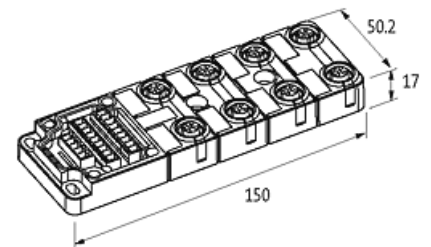

Product may differ from Image