

MICO BASIC 4.4 electronic circuit protection, 4 CHANNELS

IN: 24 V DC OUT: 24 V / 4 A

MICO BASIC 4.4
4 channels
Current adjustment 4 A

[Link to Product](#)**Illustration**

Product may differ from Image

Approvals**Input**

Operating voltage	24 V DC (18...30 V DC)
-------------------	------------------------

Output

Current adjustment	4 A
Inrush capacity	max. 20 mF (per channel)

Control inputs

Input voltage (ON)	10...30 V DC
Impulse length (ON)	min. 20 ms

Control outputs

Group alarm output	max. 20 mA; high: all channels ON; low: not all channels ON
--------------------	---

General data



Connection	Spring clamp terminals
Input terminals	1 × 16 mm ²
Output terminals	per output 1 × 4 mm ²
Alarm terminals	2.5 mm ²
Bridging concept	one side, with spring clamp terminals or bridge set (max. 40 A)
Mounting method	DIN-rail mountable TH35 (EN 60715)
Dimensions H×W×D	90×36×80 mm

Temperature range 0...+55 °C (storage temperature -40...+80 °C)

Commercial data

country of origin	CZ
customs tariff number	85363010
EAN	4048879332415
eClass	27141901
Packaging unit	1

Sketch

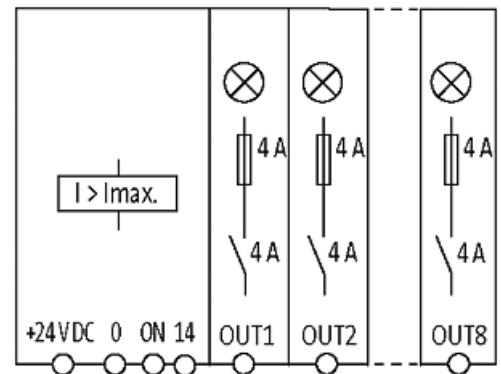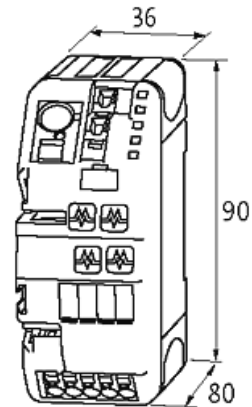

Product may differ from Image