


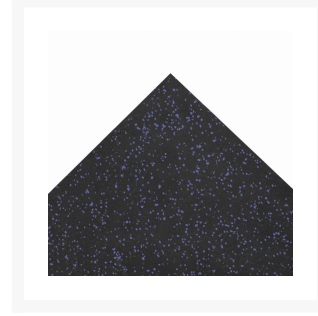
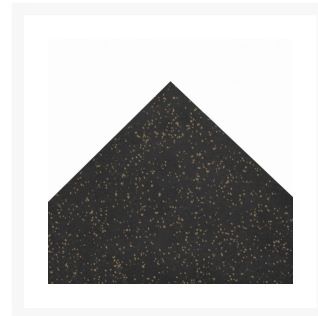
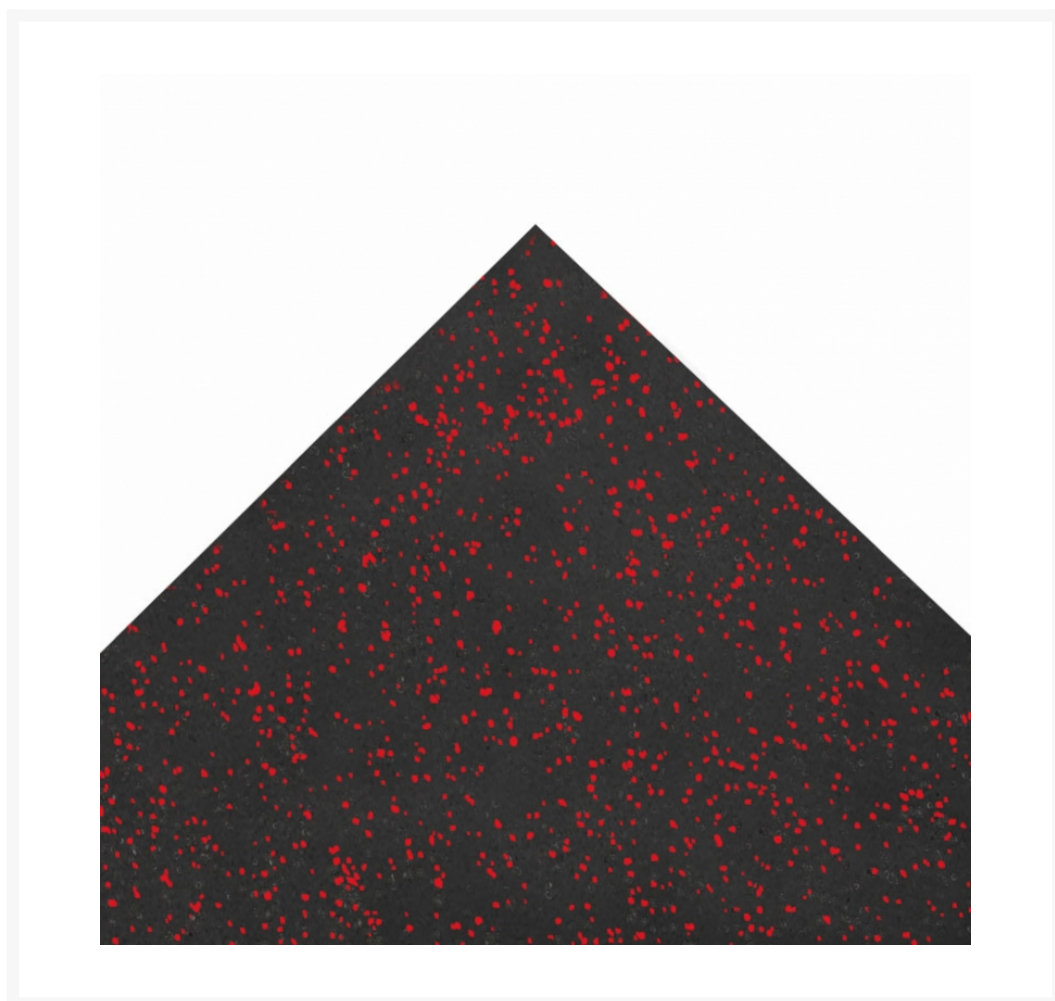


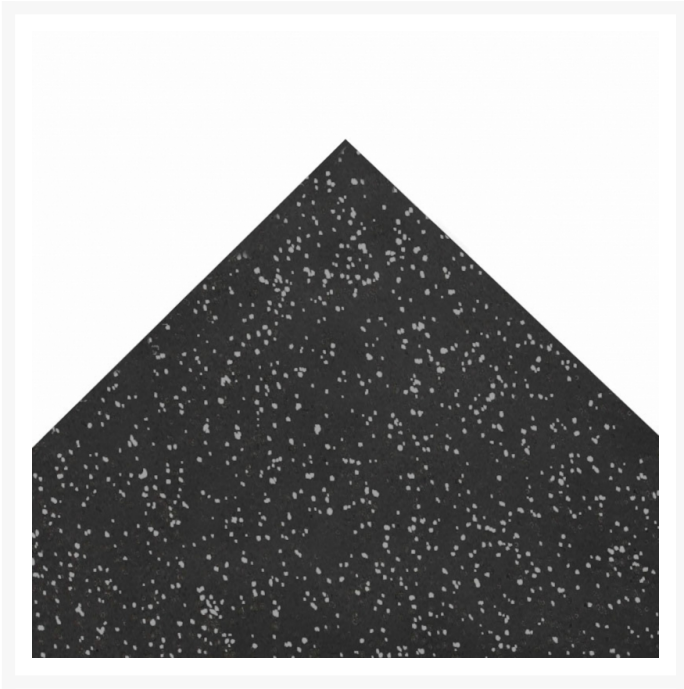

Shock & Slip Resistant Floor Protector RR Rolls 049

Product Images

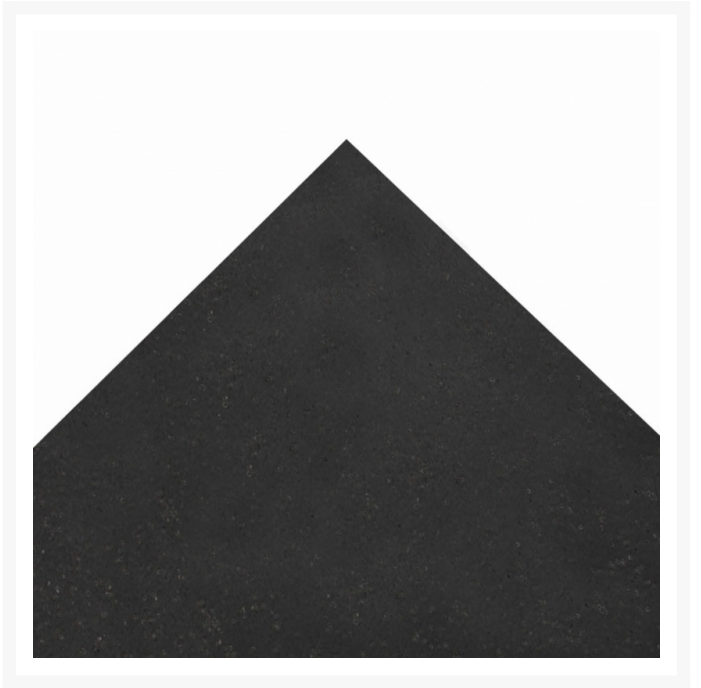

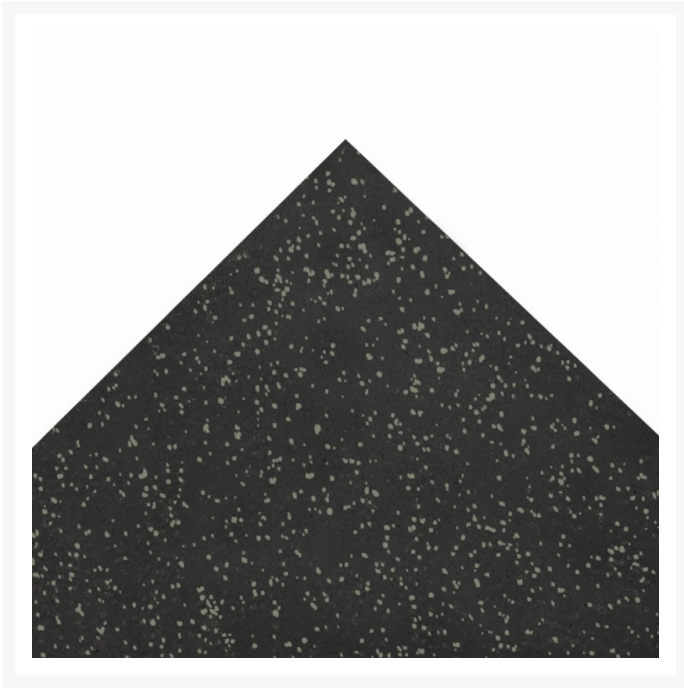



Short Description

- Environmentally friendly resilient non-porous flooring
- Shock Absorbent. Slip Resistant (Wet & Dry Areas).
- Not effected by cold weather; will not expand or become brittle or hard
- Will not harbor or promote bacteria
- Two thicknesses available:
 - 1/4" (6.35mm) – for most gyms, utility & commercial applications
 - 3/8" (9.5mm) – for heavy duty gyms & commercial applications

Description

Made of 100% recycled rubber, RR Rolls feature a dense construction that provides high impact durability making it also scuff and stain resistant. Combine anti-fatigue and ergonomic comfort properties with minimal maintenance and is slip resistance in both wet or dry conditions. The product is suitable for indoor applications that require resilience, sound absorption, spike resistance and has high traction even when wet. RR Rolls are resistant to water based liquids including urine. For light-duty applications, temporary or portable, rolls can be laid directly on floor with no glue or adhesive required. Where there will not be heavy objects dropped on the ground or equipment being moved or dragged across the floor frequently, double-sided tape at the perimeter and seams is recommended. For heavy-duty or industrial type applications, where there is pneumatic tire traffic (forklifts) or heavy foot traffic, it is recommended to glue mat down to the floor.

Specifications

Model No	049
Available Colors	Black; Blue; Eggshell; Gray; Red; Tan
Overall Thickness	1/4; 3/8
Custom Lengths	4' widths (up to 120' long) *min order qty is 30' and in 5' increments thereafter
Group	Ergonomic, Anti-fatigue & Safety Matting
Environment	Indoor/Outdoor
Recommended Use	Areas where heavy industrial equipment is stored. It is also suitable for gyms, weight rooms, skating rinks, golf courses, trailers and stables.
Surface	Raised Grid Pattern
Edges	No borders
Usage Intensity	Heavy duty
Cleaning Remark	Cleaners containing a wax agent are not recommended, as the wax can cause build up. DO NOT use petroleum-based cleaners on the mats, as these can cause deterioration.
Material Specifications	Tough rubber compound
Process	Compression Molding
Weight Lbs/sqft	1.25
Anti-Fatigue Rating	Better
Slip Resistance Rating	Better
Wear Resistance Rating	Better

Product Options

Color:	Black
	Blue
	Eggshell
	Gray
	Red
	Tan
Dimensions:	4ft x Specify Length
thickness_filter:	1/4in
	3/8in