


Anti-Slip Mat Roll, RT Trax[®], 058

Product Images

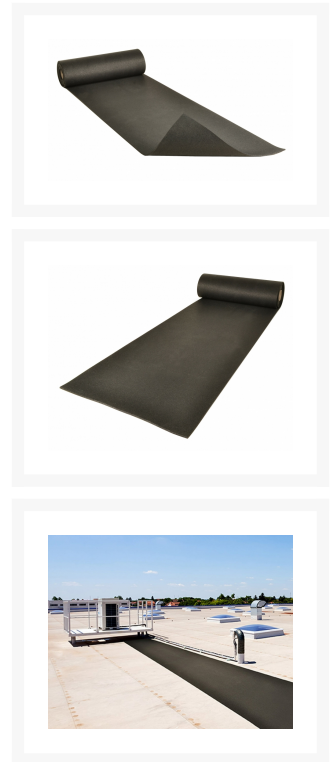

Short Description

- Slip resistant surface with the highest coefficient of friction on the market
- Smooth top surface is resistant to extreme temperature variations, UV light and moisture
- Will not warp, chip, crack, crumble, or corrode
- Made of recycled rubber
- Made for use on rooftops

Description

RT TRAX® is designed to eliminate membrane surface wear and reduce membrane punctures when facing repetitive foot traffic. Made from 100% recycled rubber, this odorless, single-ply, non-laminated flooring is a cost-efficient solution. RT Trax® has the highest coefficient of friction on the market, making the mat resistant to extreme temperature variations, UV light and moisture. Mat is available in the roll size of 30" x 30' with 5/16" thickness and are homogenous in composition and uniform in width and thickness, allowing for smoother installations in a shorter period-of-time. Perfect for roofs walkways.

Specifications

Model No	058R3030BL
Color	Black
Dimensions	30ft x 30ft
Thickness	5/16in
UPC	662641924932
Overall Thickness	5/16
Roll Sizes	30"x30'
Group	Ergonomic, Anti-fatigue & Safety Matting
Environment	Dry Areas
Recommended Use	Areas where heavy industrial equipment is stored. It is also suitable for gyms, weight rooms, skating rinks, golf courses, trailers and stables.
Surface	Raised Grid Pattern
Edges	No borders
Usage Intensity	Heavy duty
Cleaning Remark	Cleaners containing a wax agent are not recommended, as the wax can cause build up. DO NOT use petroleum-based cleaners on the mats, as these can cause deterioration.
Material Specifications	Tough rubber compound
Process	Compression Molding
Weight Lbs/sqft	1.53
Thickness Inch	5/16in
Anti-Fatigue Rating	Better
Slip Resistance Rating	Best
Wear Resistance Rating	Best