





Low Profile Light Weight Chevron Floor Runner, 105

Product Images

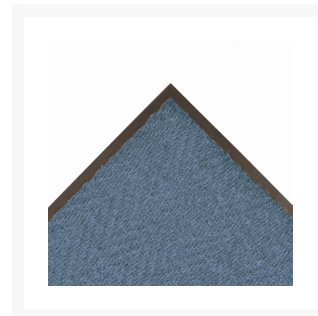



SIZE AND DIMENSION

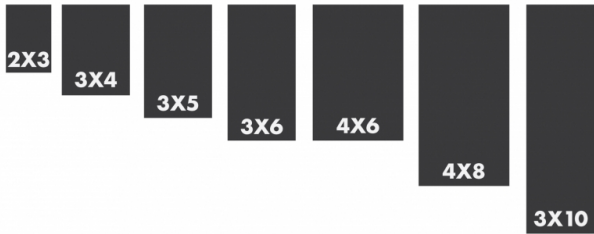

FEATURES AND BENEFITS



Low profile to perform in narrow clearance doorways.

Tightly looped carpet hides dirt and retains moisture.



Short Description

- Popular lighter-weight chevron high/low carpet design is attractive and functional as it scrapes debris from shoes regardless of traffic flow
- 18 ounces of needle-punched yarn per square yard
- Carpet made of 25% post industrial and consumer recycled content
- Low profile entrance mat to perform in narrow clearance doorways
- Vinyl backing ensures minimal buckling and mat movement

Description

This chevron floor runner entrance mat provides distinctive styling and easy maintenance in one mat. Popular chevron carpet design scrapes debris from shoes regardless of the traffic flow. Chevron is the perfect choice for any light to medium traffic areas including entranceways and lobbies.

Specifications

Model No	105
Available Colors	Brown; Charcoal; Slate Blue
Overall Thickness	5/16
Roll Sizes	3'x 60'; 4'x 60'; 6'x 60'
Custom Lengths	3', 4' and 6' widths (up to 60' long)
Standard sizes	2'x 3'; 3'x 4'; 3'x 5'; 3'x 6'; 3'x 10'; 4'x 6'; 4'x 8'
Group	Entrance Matting
Environment	Indoor
Recommended Use	For placement inside entrances of schools, offices, shops
Special Remarks	This mat has more carpet per square yard than most look-alike competitive products
Surface	Chevron Pattern
Edges	Vinyl borders
Usage Intensity	Light traffic
Backing	Black vinyl (DOP free)
Process	Needle punched
Pile Weight Oz	24
Weight Lbs/sqft	0.75
Fire Rating US	Pass
REACH Compliant	Reach compliant (Registration, Evaluation, Authorization and Restriction of Chemicals).
Dust Control Rating	Better
Water Retention Rating	Better
Crush Resistance Rating	Better
Wear Resistance Rating	Better
Function Appearance Rating	Better

Product Options

Color:	Brown
	Charcoal
	Slate Blue
Dimensions:	2ft x 3ft
	3ft x 10ft
	3ft x 4ft
	3ft x 5ft
	3ft x 60ft
	3ft x 6ft
	3ft x Specify Length
	4ft x 60ft
	4ft x 6ft
	4ft x 8ft
	4ft x Specify Length
	6ft x 60ft
	6ft x Specify Length