




# Low Profile Entry Rug Mat, Brush Step®, 109

## Product Images

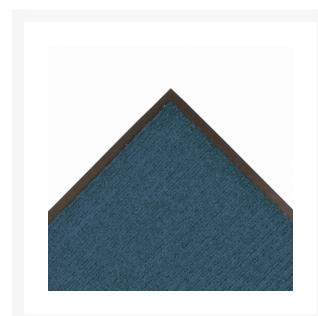





## Short Description

---

- Lighter-weight double rib high/low design that performs the scraping function of the mat (Note: ribs run length of mat)
- Solution dyed to prevent fading
- 16 ounces of needle-punched yarn per square yard
- Carpet made of 25% post industrial and consumer recycled content
- Low profile entrance mat to perform in narrow clearance doorways
- Vinyl backing ensures minimal buckling and mat movement

## Description

---

The low profile entry rug Brush Step® features a lighter-weight double rib high/low design that performs the scraping function of the mat. The ribbed surface brushes, channels, and conceals dirt and debris and is the perfect choice for light to medium traffic areas.

## Specifications

---

Model No	109
Available Colors	Brown; Charcoal; Hunter Green; Red/Black; Slate Blue
Overall Thickness	5/16
Roll Sizes	3'x 60'; 4'x 60'; 6'x 60'
Custom Lengths	3', 4' and 6' widths (up to 60' long)
Standard sizes	2'x 3'; 3'x 4'; 3'x 5'; 3'x 6'; 3'x 10'; 4'x 6'; 4'x 8'
Group	Entrance Matting
Environment	Indoor
Recommended Use	For placement inside entrances of schools, offices, shops
Special Remarks	Brush Step® is comparable to most competitors' "best" rib mat
Surface	Ribbed
Edges	Vinyl borders
Usage Intensity	Light traffic
Backing	Black vinyl (DOP free)
Process	Needle punched
Pile Weight Oz	16
Weight Lbs/sqft	0.5
Fire Rating US	Pass
REACH Compliant	Reach compliant (Registration, Evaluation, Authorization and Restriction of Chemicals).
Dust Control Rating	Good
Water Retention Rating	Good
Crush Resistance Rating	Good
Function Appearance Rating	Better

## Product Options

---

Color:	Brown
	Charcoal
	Hunter Green
	Red/Black
	Slate Blue
Dimensions:	2ft x 3ft
	3ft x 10ft
	3ft x 4ft
	3ft x 5ft
	3ft x 60ft
	3ft x 6ft
	3ft x Specify Length
	4ft x 60ft
	4ft x 6ft
	4ft x 8ft
	4ft x Specify Length
	6ft x 60ft
	6ft x Specify Length