


# 4' x 6', Hunter Green, Brush Step® Entrance Mat, 109

## Product Images

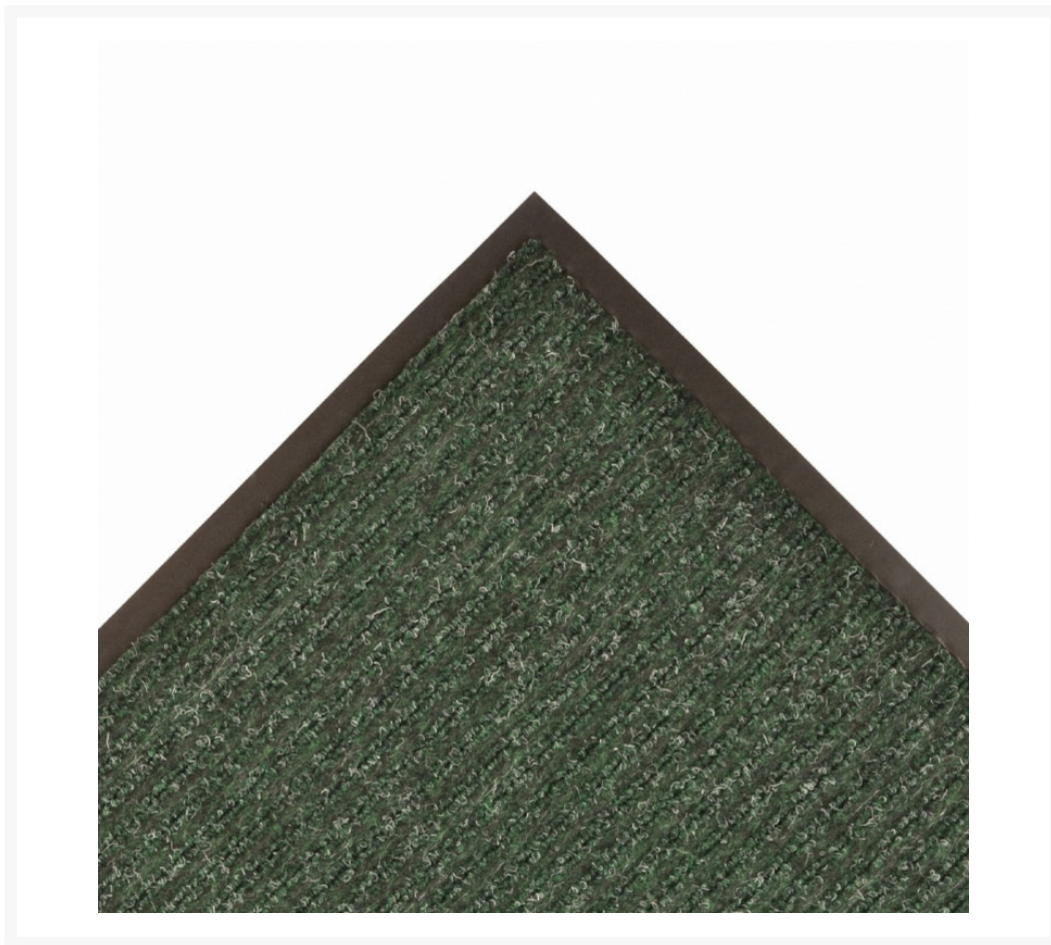

## Short Description

- **PROTECTS YOUR FLOOR** - If you're tired of having a wet/soggy entrance rug or worried about slips, trips, and falls, this all weather mat is right for you. The NoTrax floor mat is the best defense to keep water, snow, salt and debris from being tracked inside. The poly fibers absorb moisture, while the impermeable vinyl backing prevents moisture from reaching the floor.
- **EASY TO USE** - The Brush Step design has a unique double rib high/low design which helps get in between the sole tread of shoes for simple cleaning and drying. The vinyl back helps keep the rug in place to prevent slips, trips and falls. The minimalist low design makes it easy to vacuum. When used as

a door mat, it gives way for doors to easily open, and as a chairmat, allows chairs to roll freely.

- **DURABLE/LONG LASTING** -No need to worry about replacing this indoor entrance mat frequently. Its sleek design makes it suitable for areas with medium traffic. This rug has the strength of a commercial mat with a sleek design that can hold up to everyday use.

## Description

---

The low profile entry rug Brush Step® features a lighter-weight double rib high/low design that performs the scraping function of the mat. The ribbed surface brushes, channels, and conceals dirt and debris and is the perfect choice for light to medium traffic areas.

## Specifications

|                  |                                                               |
|------------------|---------------------------------------------------------------|
| Model No         | 109S0046GN                                                    |
| Color            | Hunter Green                                                  |
| Dimensions       | 4ft x 6ft                                                     |
| Thickness        | 5/16in                                                        |
| UPC              | 662641019607                                                  |
| Brand            | NoTrax                                                        |
| Available Colors | Brown; Charcoal                                               |
| Roll Sizes       | 3'x60', 4'x60', 6'x60'                                        |
| Custom Lengths   | 3', 4' and 6' widths (up to 60' long)                         |
| Standard sizes   | 2'x3', 3'x4', 3'x5', 3'x6', 3'x10', 4'x6', 4'x8'              |
| Group            | Entrance Matting                                              |
| Environment      | Indoor                                                        |
| Recommended Use  | For placement inside entrances of schools, offices, shops     |
| Special Remarks  | Brush Step® is comparable to most competitors' "best" rib mat |
| Edges            | Vinyl borders                                                 |
| Usage Intensity  | Light traffic                                                 |
| Surface Detail   | Ribbed                                                        |
| Backing          | Black vinyl (DOP free)                                        |
| Process          | Needle punched                                                |
| Pallet Quantity  | 20                                                            |
| Pile Weight Oz   | 16                                                            |
| Weight Lbs/sqft  | 0.5                                                           |
| Thickness Inch   | 5/16in                                                        |
| Fire Rating US   | Pass                                                          |

|                            |                                                                                         |
|----------------------------|-----------------------------------------------------------------------------------------|
| REACH Compliant            | Reach compliant (Registration, Evaluation, Authorization and Restriction of Chemicals). |
| Dust Control Rating        | Good                                                                                    |
| Water Retention Rating     | Good                                                                                    |
| Crush Resistance Rating    | Good                                                                                    |
| Function Appearance Rating | Better                                                                                  |