





Heavy Weight Scraper Entrance Mat Heritage Rib™ 117

Product Images

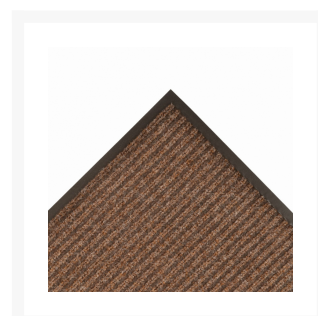

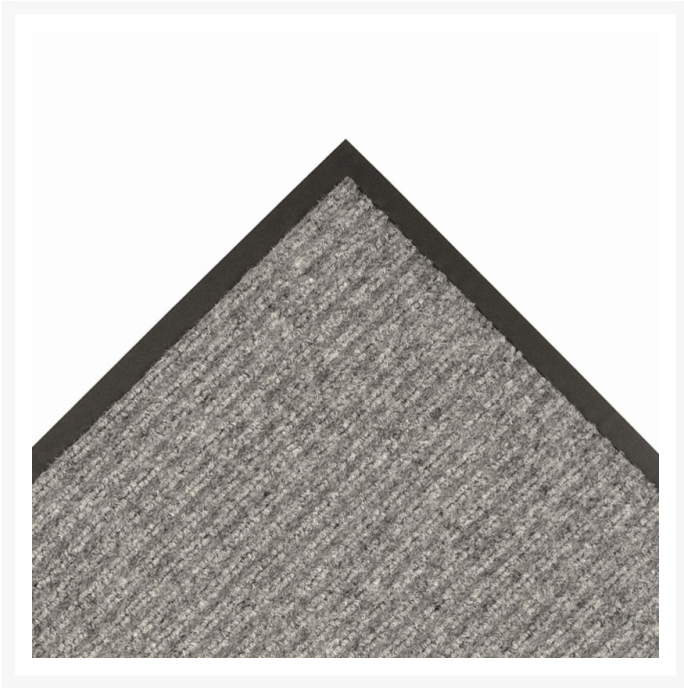



Short Description

- A heavier-weight double rib high/low design that performs the scraping function of the mat (Note: ribs run length of mat)
- 22 ounces of needle-punched yarn per square yard
- Durable crush resistant fibers provide moisture and grime retention
- Carpet made of 25% post industrial and consumer recycled content
- Low profile to perform in narrow clearance doorways
- Vinyl backing ensures minimal buckling and mat movement

Description

Heritage Rib™ offers a heavier-weight double rib high/low design that performs the scraping function of the mat. This medium to heavy traffic entrance mat is intended for areas that need extra moisture retention and scraping action. Heritage Rib™ has 33% more carpet than many competitors' "best" rib mats. Heavy-weight vinyl non-slip backing ensures minimum movement.

Specifications

Model No	117
Available Colors	Brown; Charcoal; Gray; Green; Red/Black
Overall Thickness	3/8
Roll Sizes	3'x 60'; 4'x 60'; 6'x 60'
Custom Lengths	3', 4' and 6' widths (up to 60' long)
Standard sizes	2'x 3'; 3'x 4'; 3'x 5'; 3'x 6'; 3'x 10'; 4'x 6'; 4'x 8'
Group	Entrance Matting
Environment	Indoor
Recommended Use	For placement inside entrances of schools, offices, shops
Special Remarks	Heritage Rib™ has 33% more carpet than many competitors' "best" Rib mats
Surface	Ribbed
Edges	Vinyl borders
Usage Intensity	Medium traffic
Backing	Black vinyl (DOP free)
Process	Needle punched
Pile Weight Oz	22
Weight Lbs/sqft	0.7
Fire Rating US	Pass
REACH Compliant	Reach compliant (Registration, Evaluation, Authorization and Restriction of Chemicals).
Dust Control Rating	Better
Water Retention Rating	Better
Crush Resistance Rating	Best
Function Appearance Rating	Best

Product Options

Color:	Brown
	Charcoal
	Gray
	Green
	Red/Black
Dimensions:	2ft x 3ft
	3ft x 10ft
	3ft x 4ft
	3ft x 5ft
	3ft x 60ft
	3ft x 6ft
	3ft x Specify Length
	4ft x 60ft
	4ft x 6ft
	4ft x 8ft
	4ft x Specify Length
	6ft x 60ft
	6ft x Specify Length