



6' x 60', Charcoal, Heritage Rib™ Scraper Entrance Mat, 117

Product Images

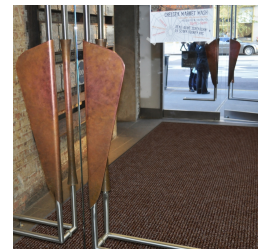

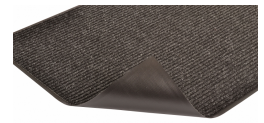

Short Description

- A heavier-weight double rib high/low design that performs the scraping function of the mat (Note: ribs run length of mat)
- 22 ounces of needle-punched yarn per square yard
- Low profile to perform in narrow clearance doorways
- Vinyl backing ensures minimal buckling and mat movement

Description

Heritage Rib™ offers a heavier-weight double rib high/low design that performs the scraping function of the mat. This medium to heavy traffic entrance mat is intended for areas that need extra moisture retention and scraping action. Heritage Rib™ has 33% more carpet than many competitors' "best" rib mats. Heavy-weight vinyl non-slip backing ensures minimum movement.

Specifications

Model No	117R0072CH
Color	Charcoal
Dimensions	6ft x 60ft
Thickness	3/8in
UPC	662641607583
Brand	NoTrax
Available Colors	Brown; Charcoal; Green; Red/Black
Roll Sizes	3'x60', 4'x60', 6'x60'
Custom Lengths	3', 4' and 6' widths (up to 60' long)
Standard sizes	2'x3', 3'x4', 3'x5', 3'x6', 3'x10', 4'x6', 4'x8'
Group	Entrance Matting
Environment	Indoor
Recommended Use	For placement inside entrances of schools, offices, shops
Special Remarks	Heritage Rib™ has 33% more carpet than many competitors' "best" Rib mats
Edges	Vinyl borders
Usage Intensity	Medium traffic
Surface Detail	Ribbed
Backing	Black vinyl (DOP free)
Process	Needle punched
Pallet Quantity	4
Pile Weight Oz	22
Weight Lbs/sqft	0.7
Thickness Inch	3/8in
Fire Rating US	Pass

REACH Compliant	Reach compliant (Registration, Evaluation, Authorization and Restriction of Chemicals).
Dust Control Rating	Better
Water Retention Rating	Better
Crush Resistance Rating	Best
Function Appearance Rating	Best