


3' x 4', Green, Heritage Rib™ Scraper Entrance Mat, 117

Product Images

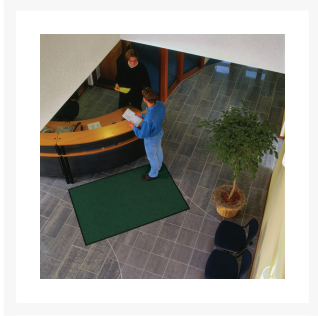

Short Description

- A heavier-weight double rib high/low design that performs the scraping function of the mat (Note: ribs run length of mat)
- 22 ounces of needle-punched yarn per square yard
- Low profile to perform in narrow clearance doorways
- Vinyl backing ensures minimal buckling and mat movement

Description

Heritage Rib™ offers a heavier-weight double rib high/low design that performs the scraping function of the mat. This medium to heavy traffic entrance mat is intended for areas that need extra moisture retention and scraping action. Heritage Rib™ has 33% more carpet than many competitors' "best" rib mats. Heavy-weight vinyl non-slip backing ensures minimum movement.

Specifications

Model No	117S0034GN
Color	Green
Dimensions	3ft x 4ft
Thickness	3/8in
UPC	662641607958
Available Colors	Brown; Charcoal; Green; Red/Black
Roll Sizes	3'x60', 4'x60', 6'x60'
Custom Lengths	3', 4' and 6' widths (up to 60' long)
Standard sizes	2'x3', 3'x4', 3'x5', 3'x6', 3'x10', 4'x6', 4'x8'
Group	Entrance Matting
Environment	Indoor
Recommended Use	For placement inside entrances of schools, offices, shops
Special Remarks	Heritage Rib™ has 33% more carpet than many competitors' "best" Rib mats
Surface	Ribbed
Edges	Vinyl borders
Usage Intensity	Medium traffic
Backing	Black vinyl (DOP free)
Process	Needle punched
Pile Weight Oz	22
Weight Lbs/sqft	0.7
Thickness Inch	3/8in
Fire Rating US	Pass
REACH Compliant	Reach compliant (Registration, Evaluation, Authorization and Restriction of Chemicals).
Dust Control Rating	Better

Water Retention Rating	Better
------------------------	--------

Crush Resistance Rating	Best
-------------------------	------

Function Appearance Rating	Best
----------------------------	------