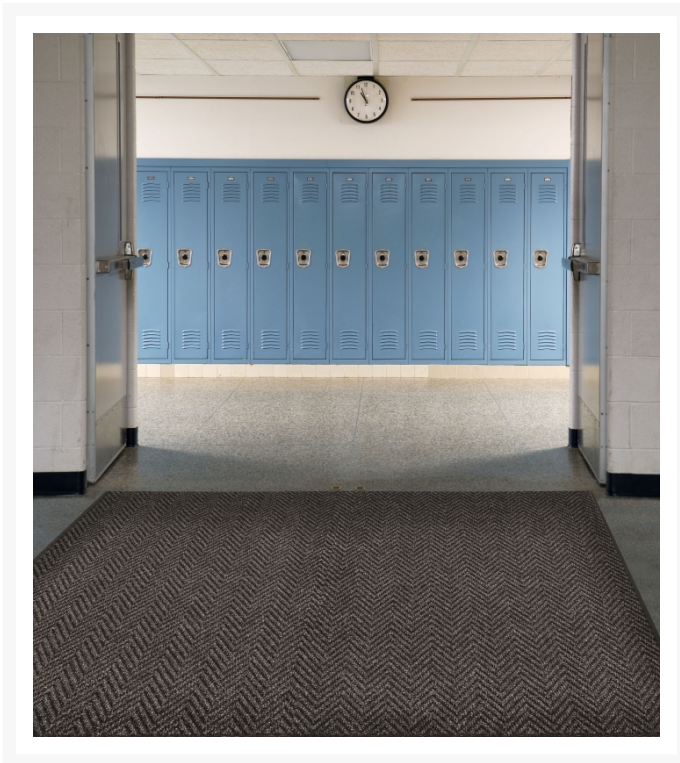

Low Profile Scraper Entrance Mat Arrow Trax[®] 118

Product Images







Short Description

- The high/low herringbone carpet design is attractive and functional as it scrapes debris and channels it away from shoes regardless of traffic flow
- A full 40 ounces of needle-punched yarn per square yard
- Durable crush resistant fibers provide moisture and grime retention
- Low profile to perform in narrow clearance doorways
- Vinyl backing ensures minimal buckling and mat movement

Description

Arrow Trax® mats provide exceptional performance in highly visible areas that require a subtly attractive yet functional matting product. The durable herringbone pattern offers non-directional scraping action and moisture retention, and a full 40 ounces of needle-punched yarn per square yard provides the highest degree of crush resistance in heavy traffic areas. Heavy-weight vinyl non-slip backing ensures minimum movement.

Specifications

Model No	118
Available Colors	Brown; Charcoal; Gray
Overall Thickness	3/8
Roll Sizes	3'x 60'; 4'x 60'; 6'x 60'
Custom Lengths	3', 4' and 6' widths (up to 60' long)
Standard sizes	2'x 3'; 3'x 4'; 3'x 5'; 3'x 6'; 3'x 10'; 4'x 6'; 4'x 8'
Group	Entrance Matting
Environment	Indoor
Recommended Use	For placement inside entrances in schools, universities, public buildings, sports facilities, shopping malls
Special Remarks	A combination of 4 deniers of yarn make this an extremely long-lasting mat
Surface	Chevron Pattern
Edges	Vinyl borders
Usage Intensity	Heavy traffic
Backing	Black vinyl (DOP free)
Process	Needle punched
Pile Weight Oz	40
Weight Lbs/sqft	0.7
Fire Rating US	Pass
REACH Compliant	Reach compliant (Registration, Evaluation, Authorization and Restriction of Chemicals).
Dust Control Rating	Best
Water Retention Rating	Best
Crush Resistance Rating	Best
Function Appearance Rating	Superior

Product Options

Color:	Brown
	Charcoal
	Gray
Dimensions:	2ft x 3ft
	3ft x 10ft
	3ft x 4ft
	3ft x 5ft
	3ft x 60ft
	3ft x 6ft
	3ft x Specify Length
	4ft x 60ft
	4ft x 6ft
	4ft x 8ft
	4ft x Specify Length
	6ft x 60ft
	6ft x Specify Length