


3' x 4', Brown, Arrow Trax® Low Profile Scraper Entrance Mat, 118

Product Images

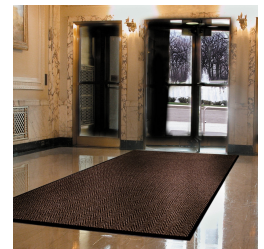

Short Description

- The high/low herringbone carpet design is attractive and functional as it scrapes debris and channels it away from shoes regardless of traffic flow
- A full 40 ounces of needle-punched yarn per square yard
- Low profile to perform in narrow clearance doorways
- Vinyl backing ensures minimal buckling and mat movement

Description

Arrow Trax® mats provide exceptional performance in highly visible areas that require a subtly attractive yet functional matting product. The durable herringbone pattern offers non-directional scraping action and moisture retention, and a full 40 ounces of needle-punched yarn per square yard provides the highest degree of crush resistance in heavy traffic areas. Heavy-weight vinyl non-slip backing ensures minimum movement.

Specifications

Model No	118S0034BR
Color	Brown
Dimensions	3ft x 4ft
Thickness	3/8in
UPC	662641609198
Brand	NoTrax
Special Price Type	Sale
Available Colors	Autumn Black; Brown; Charcoal; Gray
Roll Sizes	3'x60', 4'x60', 6'x60'
Custom Lengths	3', 4' and 6' widths (up to 60' long)
Standard sizes	2'x3', 3'x4', 3'x5', 3'x6', 3'x10', 4'x6', 4'x8'
Group	Entrance Matting
Environment	Indoor
Recommended Use	For placement inside entrances in schools, universities, public buildings, sports facilities, shopping malls
Special Remarks	A combination of 4 deniers of yarn make this an extremely long-lasting mat
Edges	Vinyl borders
Usage Intensity	Heavy traffic
Surface Detail	Chevron Pattern
Backing	Black vinyl (DOP free)
Process	Needle punched
Pallet Quantity	36
Pile Weight Oz	40
Weight Lbs/sqft	0.7
Thickness Inch	3/8in
Fire Rating US	Pass

REACH Compliant	Reach compliant (Registration, Evaluation, Authorization and Restriction of Chemicals).
Dust Control Rating	Best
Water Retention Rating	Best
Crush Resistance Rating	Best
Function Appearance Rating	Superior