



# Debris Trapping Entrance Mat Polynib™ 136

## Product Images

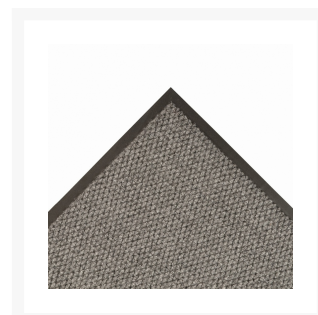

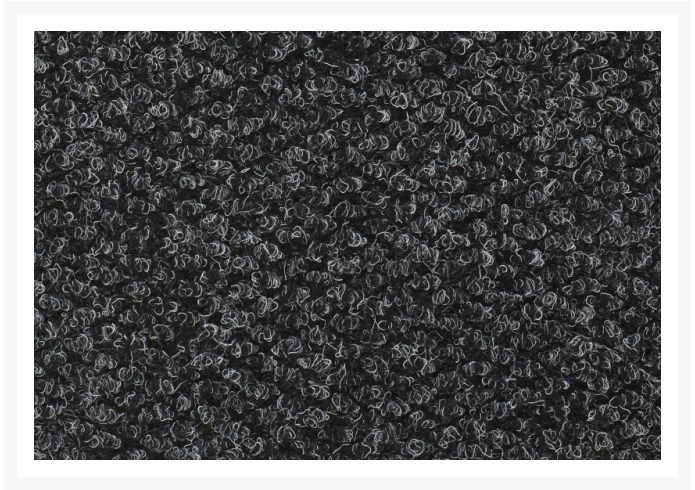

## Short Description

- Tightly nibbed loop that entraps debris and hides it for an always elegant appearance
- 18 ounces of needle-punched yarn per square yard

- Carpet made of 25% post industrial and consumer recycled content
- Low profile entrance mat to perform in narrow clearance doorways
- Vinyl backing ensures minimal buckling and mat movement

## Description

---

Polynib™ entrance mat has the rich, luxurious look of Berber-style carpeting for an always elegant appearance. A very tightly nibbed loop of needle-punched yarn entraps and hides debris while retaining moisture at the same time. 18 ounces of carpet per square yard provides greater crush resistance for long lasting wear. Polynib™ comes with a heavy-weight vinyl non-slip backing ensures minimum movement.

## Specifications

---

Model No	136
Available Colors	Brown; Charcoal; Gray
Overall Thickness	3/8
Roll Sizes	3'x 60'; 4'x 60'; 6'x 60'
Custom Lengths	3', 4' and 6' widths (up to 60' long)
Standard sizes	2'x 3'; 3'x 4'; 3'x 5'; 3'x 6'; 3'x 10'; 4'x 6'; 4'x 8'
Group	Entrance Matting
Environment	Indoor
Recommended Use	For placement inside entrances of schools, offices, shops
Special Remarks	A European look suitable for a more modern décor
Surface	Nibbed
Edges	Vinyl borders
Usage Intensity	Medium traffic
Installation	Roll out and lay flat
Backing	Black vinyl (DOP free)
Process	Needle punched
Pile Weight Oz	24
Weight Lbs/sqft	0.6
Fire Rating US	Pass
REACH Compliant	Reach compliant (Registration, Evaluation, Authorization and Restriction of Chemicals).
Dust Control Rating	Better
Water Retention Rating	Better
Crush Resistance Rating	Best
Function Appearance Rating	Best

## Product Options

---

Color:	Brown
	Charcoal
	Gray
Dimensions:	2ft x 3ft
	3ft x 10ft
	3ft x 4ft
	3ft x 5ft
	3ft x 60ft
	3ft x 6ft
	3ft x Specify Length
	4ft x 60ft
	4ft x 6ft
	4ft x 8ft
	4ft x Specify Length
	6ft x 60ft
	6ft x Specify Length