


3' x Custom Length, Gray, Polynib™ Debris Trapping Entrance Mat, 136

Product Images

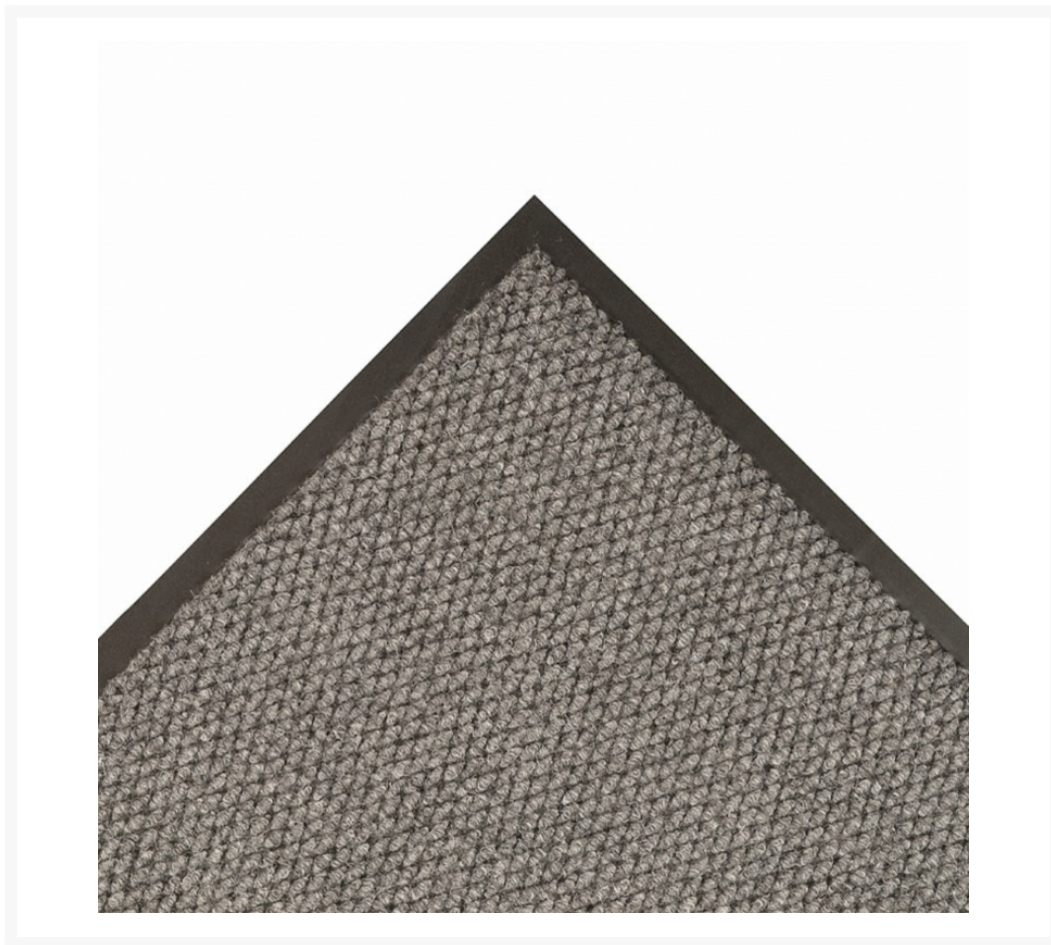

Short Description

- Tightly nibbed loop that entraps debris and hides it for an always elegant appearance
- 24 ounces of needle-punched yarn per square yard
- Low profile entrance mat to perform in narrow clearance doorways
- Vinyl backing ensures minimal buckling and mat movement

Description

Polynib™ entrance mat has the rich, luxurious look of Berber-style carpeting for an always elegant appearance. A very tightly nibbed loop of needle-punched yarn entraps and hides debris while retaining moisture at the same time. 24 ounces of carpet per square yard provides greater crush resistance for long lasting wear. Polynib™ comes with a heavy-weight vinyl non-slip backing ensures minimum movement.

Specifications

Model No	136C0036GY
Color	Gray
Dimensions	3ft x Specify Length
Thickness	3/8in
UPC	662641009707
Brand	NoTrax
Special Price Type	Sale
Available Colors	Blue; Brown; Charcoal
Roll Sizes	3'x60', 4'x60', 6'x60'
Custom Lengths	3', 4' and 6' widths (up to 60' long)
Standard sizes	2'x3', 3'x4', 3'x5', 3'x6', 3'x10', 4'x6', 4'x8'
Group	Entrance Matting
Environment	Indoor
Recommended Use	For placement inside entrances of schools, offices, shops
Special Remarks	A European look suitable for a more modern décor
Edges	Vinyl borders
Usage Intensity	Medium traffic
Installation	Roll out and lay flat
Surface Detail	Nibbed
Backing	Black vinyl (DOP free)
Process	Needle punched
Pile Weight Oz	24
Weight Lbs/sqft	0.6
Thickness Inch	3/8in
Fire Rating US	Pass

REACH Compliant	Reach compliant (Registration, Evaluation, Authorization and Restriction of Chemicals).
Dust Control Rating	Better
Water Retention Rating	Better
Crush Resistance Rating	Best
Function Appearance Rating	Best