


# 4' x Custom Length, Gray, Polynib™ Debris Trapping Entrance Mat, 136

## Product Images

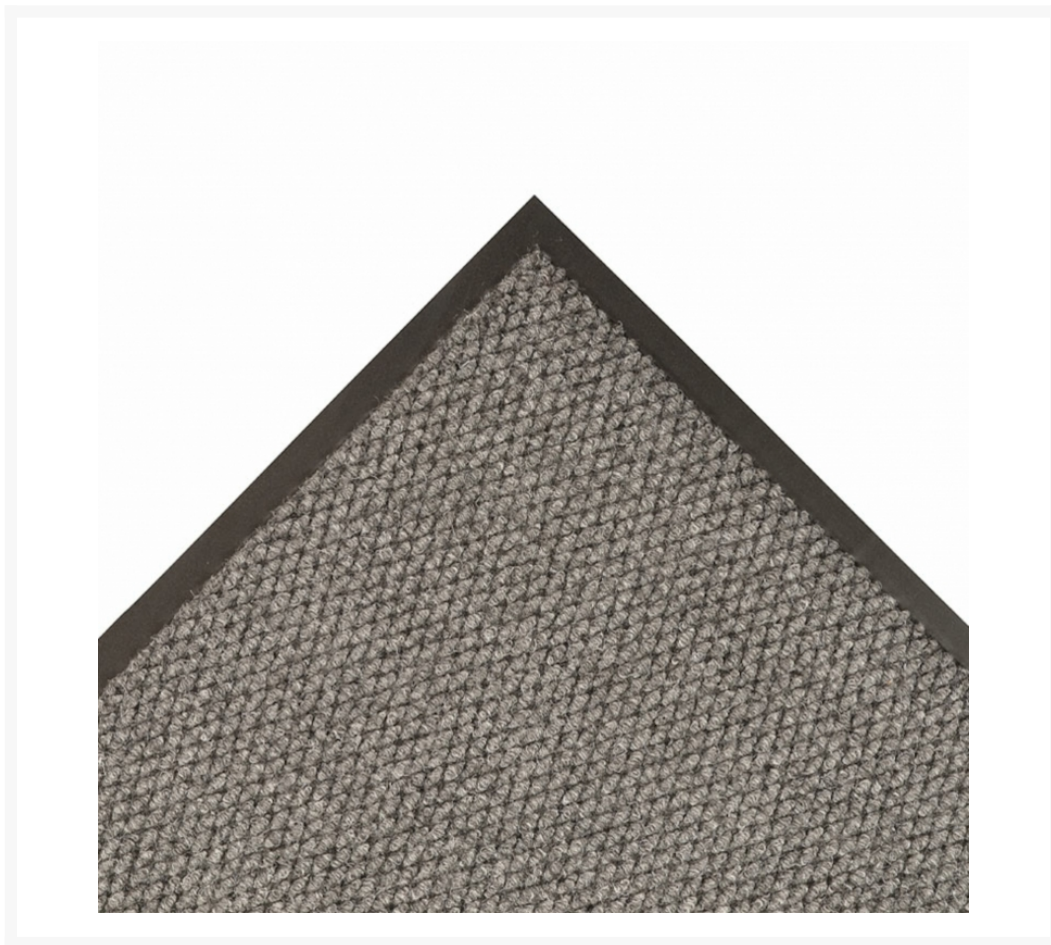

## Short Description

- Tightly nibbed loop that entraps debris and hides it for an always elegant appearance
- 24 ounces of needle-punched yarn per square yard
- Low profile entrance mat to perform in narrow clearance doorways
- Vinyl backing ensures minimal buckling and mat movement

## Description

---

Polynib™ entrance mat has the rich, luxurious look of Berber-style carpeting for an always elegant appearance. A very tightly nibbed loop of needle-punched yarn entraps and hides debris while retaining moisture at the same time. 24 ounces of carpet per square yard provides greater crush resistance for long lasting wear. Polynib™ comes with a heavy-weight vinyl non-slip backing ensures minimum movement.

## Specifications

|                  |                                                                                         |
|------------------|-----------------------------------------------------------------------------------------|
| Model No         | 136C0048GY                                                                              |
| Color            | Gray                                                                                    |
| Dimensions       | 4ft x Specify Length                                                                    |
| Thickness        | 3/8in                                                                                   |
| UPC              | 662641009752                                                                            |
| Brand            | NoTrax                                                                                  |
| Available Colors | Blue; Brown; Charcoal                                                                   |
| Roll Sizes       | 3'x60', 4'x60', 6'x60'                                                                  |
| Custom Lengths   | 3', 4' and 6' widths (up to 60' long)                                                   |
| Standard sizes   | 2'x3', 3'x4', 3'x5', 3'x6', 3'x10', 4'x6', 4'x8'                                        |
| Group            | Entrance Matting                                                                        |
| Environment      | Indoor                                                                                  |
| Recommended Use  | For placement inside entrances of schools, offices, shops                               |
| Special Remarks  | A European look suitable for a more modern décor                                        |
| Edges            | Vinyl borders                                                                           |
| Usage Intensity  | Medium traffic                                                                          |
| Installation     | Roll out and lay flat                                                                   |
| Surface Detail   | Nibbed                                                                                  |
| Backing          | Black vinyl (DOP free)                                                                  |
| Process          | Needle punched                                                                          |
| Pile Weight Oz   | 24                                                                                      |
| Weight Lbs/sqft  | 0.6                                                                                     |
| Thickness Inch   | 3/8in                                                                                   |
| Fire Rating US   | Pass                                                                                    |
| REACH Compliant  | Reach compliant (Registration, Evaluation, Authorization and Restriction of Chemicals). |

|                            |        |
|----------------------------|--------|
| Dust Control Rating        | Better |
| Water Retention Rating     | Better |
| Crush Resistance Rating    | Best   |
| Function Appearance Rating | Best   |