


2' x 3', Gray, Polynib™ Debris Trapping Entrance Mat, 136

Product Images

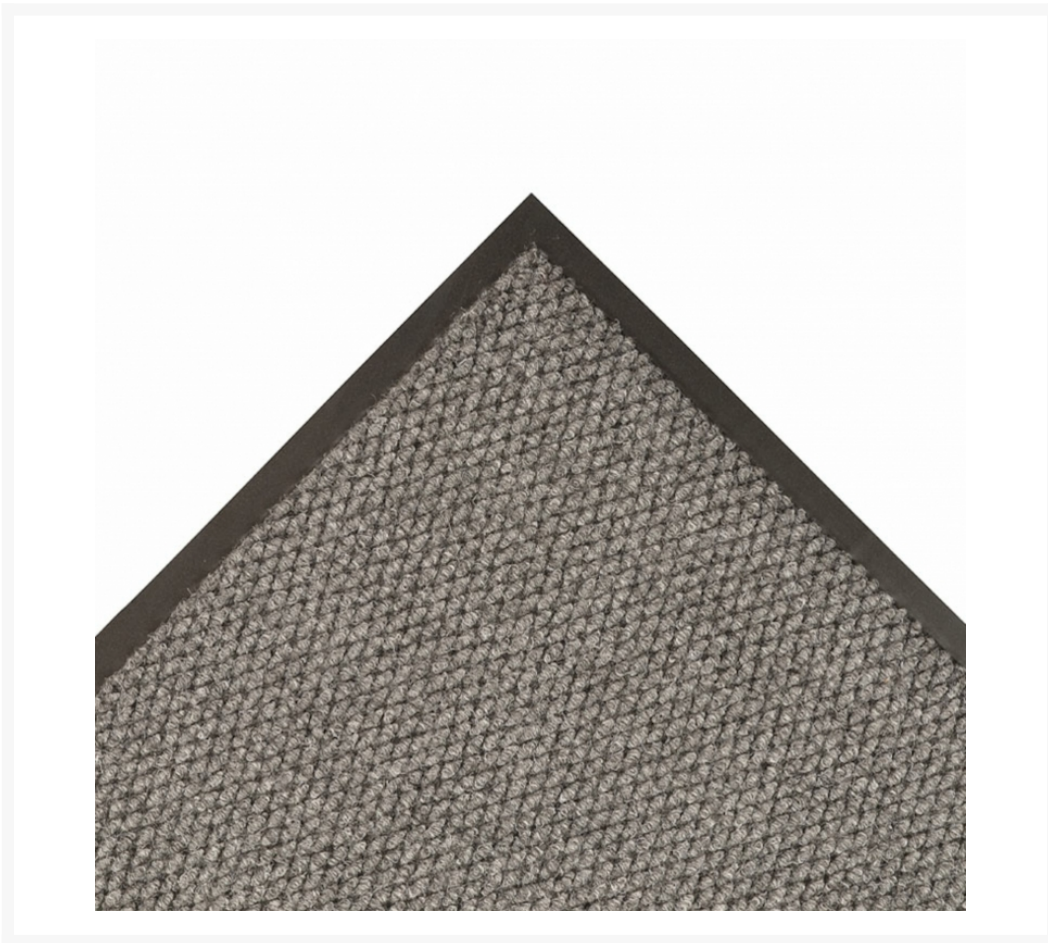

Short Description

- Tightly nibbed loop that entraps debris and hides it for an always elegant appearance
- 24 ounces of needle-punched yarn per square yard
- Low profile entrance mat to perform in narrow clearance doorways
- Vinyl backing ensures minimal buckling and mat movement

Description

Polynib™ entrance mat has the rich, luxurious look of Berber-style carpeting for an always elegant appearance. A very tightly nibbed loop of needle-punched yarn entraps and hides debris while retaining moisture at the same time. 24 ounces of carpet per square yard provides greater crush resistance for long lasting wear. Polynib™ comes with a heavy-weight vinyl non-slip backing ensures minimum movement.

Specifications

| | |
|---------------------|---|
| Model No | 136S0023GY |
| Color | Gray |
| Dimensions | 2ft x 3ft |
| Thickness | 3/8in |
| UPC | 662641009257 |
| Available Colors | Blue; Brown; Charcoal |
| Roll Sizes | 3'x60', 4'x60', 6'x60' |
| Custom Lengths | 3', 4' and 6' widths (up to 60' long) |
| Standard sizes | 2'x3', 3'x4', 3'x5', 3'x6', 3'x10', 4'x6', 4'x8' |
| Group | Entrance Matting |
| Environment | Indoor |
| Recommended Use | For placement inside entrances of schools, offices, shops |
| Special Remarks | A European look suitable for a more modern décor |
| Surface | Nibbed |
| Edges | Vinyl borders |
| Usage Intensity | Medium traffic |
| Installation | Roll out and lay flat |
| Backing | Black vinyl (DOP free) |
| Process | Needle punched |
| Pile Weight Oz | 24 |
| Weight Lbs/sqft | 0.6 |
| Thickness Inch | 3/8in |
| Fire Rating US | Pass |
| REACH Compliant | Reach compliant (Registration, Evaluation, Authorization and Restriction of Chemicals). |
| Dust Control Rating | Better |

| | |
|------------------------|--------|
| Water Retention Rating | Better |
|------------------------|--------|

| | |
|-------------------------|------|
| Crush Resistance Rating | Best |
|-------------------------|------|

| | |
|----------------------------|------|
| Function Appearance Rating | Best |
|----------------------------|------|