

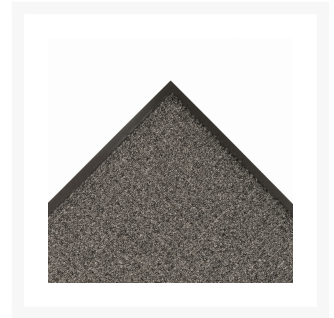
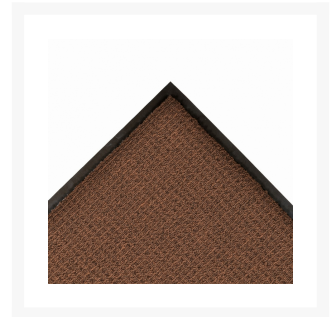
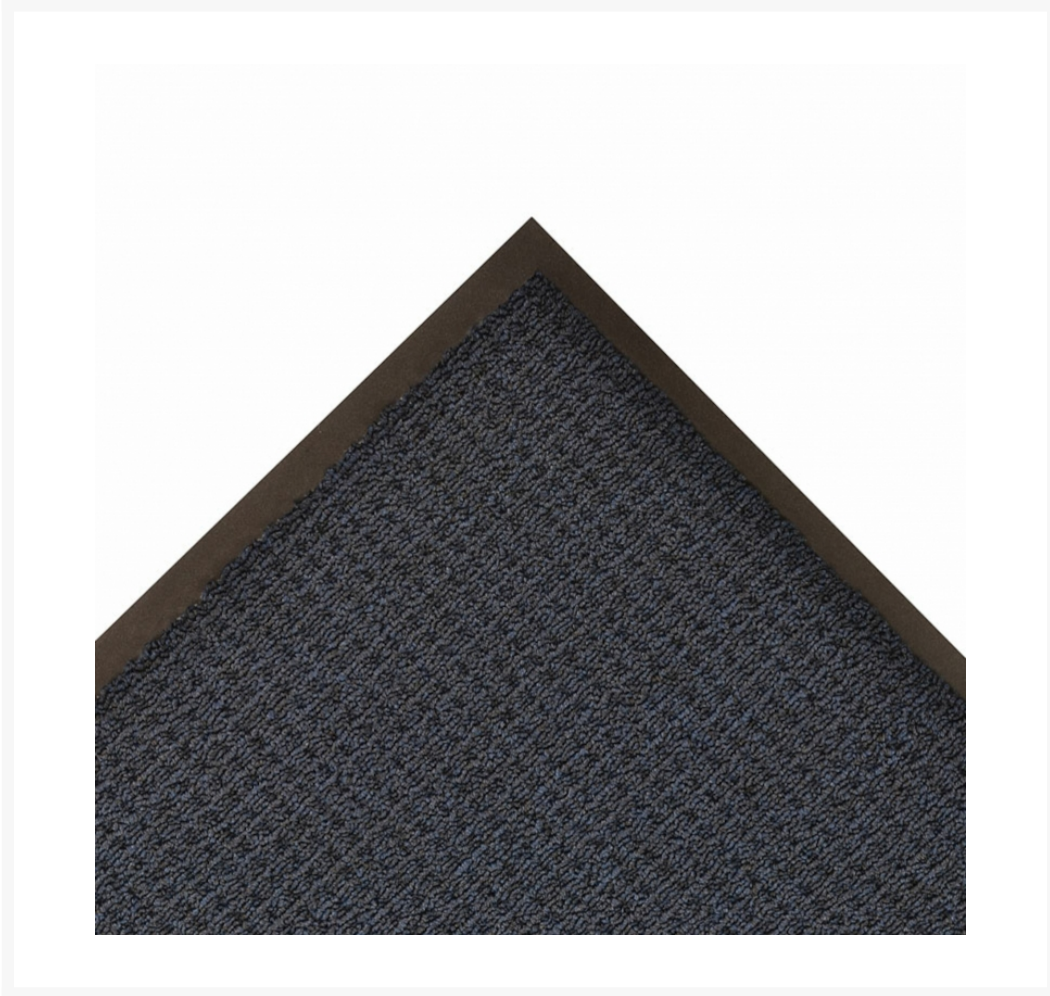


# Entrance Mat Uptown™ 138

## Product Images

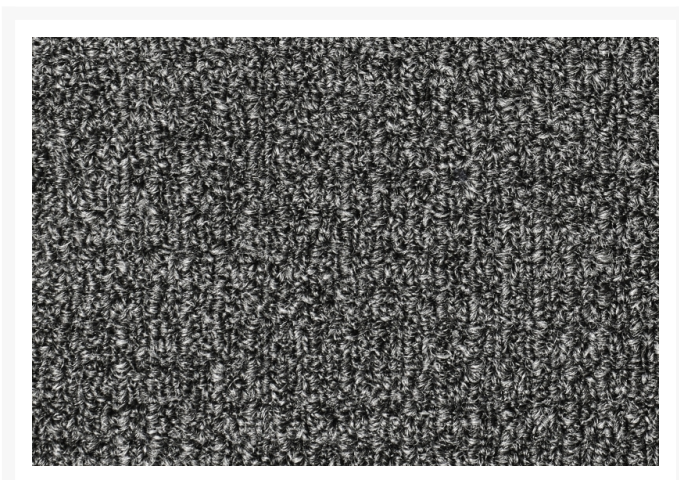

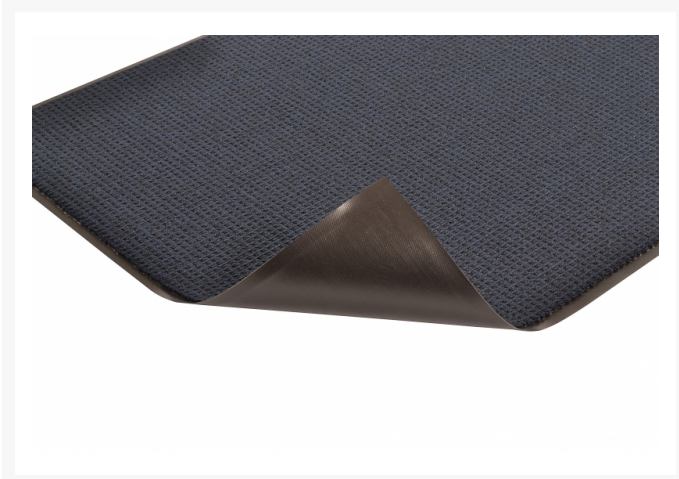

## Short Description

---

- The high/low looped pile design provides functionality for drying and retaining moisture and debris, while offering an upscale, elegant look
- A dense combination of scraping and absorbent yarns ensure maximum performance
- 36 ounces of tufted Decalon® yarn per square yard
- Low profile to perform in narrow clearance doorways
- Vinyl backing ensures minimal buckling and mat movement

## Description

---

Uptown™ is a high/low looped-pile entrance mat that provides functionality for drying and retaining moisture and debris, while offering an upscale, elegant look. Its 36 ounces of tufted Decalon® yarn per square yard offer the ultimate in moisture absorption and crush resistance standing up to the heaviest traffic areas. Uptown™ has a heavy-weight vinyl backing to ensure minimum mat movement.

## Specifications

---

Model No	138
Available Colors	Brown; Charcoal
Overall Thickness	3/8
Roll Sizes	3'x 60'; 4'x 60'; 6'x 60'
Custom Lengths	3', 4' and 6' widths (up to 60' long)
Standard sizes	2'x 3'; 3'x 4'; 3'x 5'; 3'x 6'; 3'x 10'; 4'x 6'; 4'x 8'
Group	Entrance Matting
Environment	Indoor
Recommended Use	For placement inside entrances of offices, shops, restaurants, grocery shops, bakeries, specialty stores.
Special Remarks	Upscale scrape & dry entrance matting system.
Surface	Checked Pattern
Edges	Vinyl borders
Usage Intensity	Heavy traffic
Material Specifications	Decalon® yarns
Backing	Black vinyl (DOP free)
Process	Tufting
Pile Weight Oz	36
Weight Lbs/sqft	0.6
Fire Rating US	Pass
REACH Compliant	Reach compliant (Registration, Evaluation, Authorization and Restriction of Chemicals).
Dust Control Rating	Best
Water Retention Rating	Superior
Crush Resistance Rating	Best
Function Appearance Rating	Superior

## Product Options

---

Color:	Brown
	Charcoal
	Navy
Dimensions:	2ft x 3ft
	3' X 4'
	3' X 10'
	3' x 6'
	3ft x 10ft
	3ft x 4ft
	3ft x 5ft
	3ft x 60ft
	3ft x 6ft
	3ft x Specify Length
	4' X 6'
	4ft x 60ft
	4ft x 6ft
	4ft x 8ft
	4ft x Specify Length
	6' x 60'
	6ft x 60ft
	6ft x Specify Length