



# 6' x Custom Length, Charcoal, Uptown™ Entrance Mat, 138

## Product Images

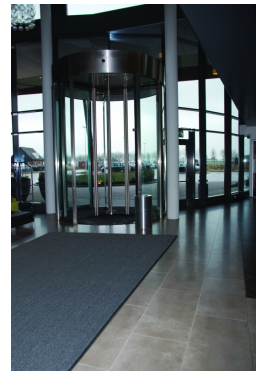

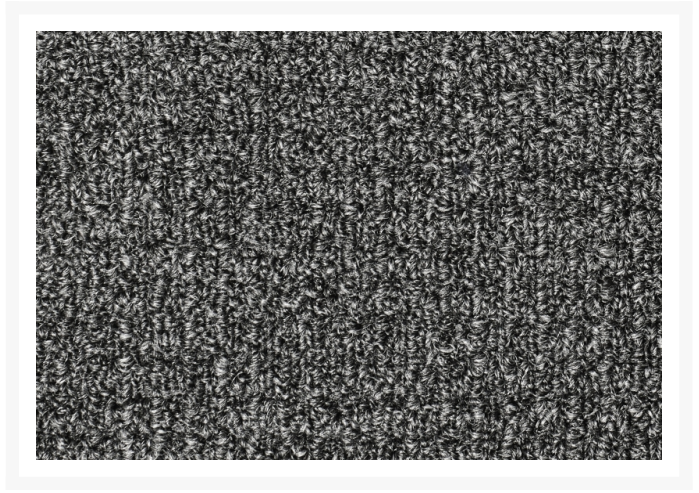

## Short Description

---

- The high/low looped pile design provides functionality for drying and retaining moisture and debris, while offering an upscale, elegant look
- A dense combination of scraping and absorbent yarns ensure maximum performance
- 36 ounces of tufted Decalon® yarn per square yard
- Low profile to perform in narrow clearance doorways
- Vinyl backing ensures minimal buckling and mat movement

## Description

---

Uptown™ is a high/low looped-pile entrance mat that provides functionality for drying and retaining moisture and debris, while offering an upscale, elegant look. Its 36 ounces of tufted Decalon® yarn per square yard offer the ultimate in moisture absorption and crush resistance standing up to the heaviest traffic areas. Uptown™ has a heavy-weight vinyl backing to ensure minimum mat movement.

## Specifications

|                         |                                                                                                           |
|-------------------------|-----------------------------------------------------------------------------------------------------------|
| Model No                | 138C0072CH                                                                                                |
| Color                   | Charcoal                                                                                                  |
| Dimensions              | 6ft x Specify Length                                                                                      |
| Thickness               | 3/8in                                                                                                     |
| UPC                     | 662641779563                                                                                              |
| Brand                   | NoTrax                                                                                                    |
| Special Price Type      | Sale                                                                                                      |
| Available Colors        | Brown; Burgundy; Charcoal; Green; Navy; Red/Black                                                         |
| Roll Sizes              | 3'x60', 4'x60', 6'x60'                                                                                    |
| Custom Lengths          | 3', 4' and 6' widths (up to 60' long)                                                                     |
| Standard sizes          | 2'x3', 3'x4', 3'x5', 3'x6', 3'x10', 4'x6', 4'x8'                                                          |
| Group                   | Entrance Matting                                                                                          |
| Environment             | Indoor                                                                                                    |
| Special Characteristics | Free of DOP, free of DMF, free of ozone depleting substances, free of silicone and free of heavy metals   |
| Recommended Use         | For placement inside entrances of offices, shops, restaurants, grocery shops, bakeries, specialty stores. |
| Special Remarks         | Upscale scrape & dry entrance matting system.                                                             |
| Edges                   | Vinyl borders                                                                                             |
| Usage Intensity         | Heavy traffic                                                                                             |
| Material Specifications | Decalon® yarns                                                                                            |
| Surface Detail          | Checked Pattern                                                                                           |
| Backing                 | Black vinyl (DOP free)                                                                                    |
| Process                 | Tufting                                                                                                   |
| Pile Weight Oz          | 36                                                                                                        |
| Weight Lbs/sqft         | 0.6                                                                                                       |
| Thickness Inch          | 3/8in                                                                                                     |

|                            |                                                                                         |
|----------------------------|-----------------------------------------------------------------------------------------|
| Fire Rating US             | Pass                                                                                    |
| REACH Compliant            | Reach compliant (Registration, Evaluation, Authorization and Restriction of Chemicals). |
| Dust Control Rating        | Best                                                                                    |
| Water Retention Rating     | Superior                                                                                |
| Crush Resistance Rating    | Best                                                                                    |
| Function Appearance Rating | Superior                                                                                |