



Non Absorbent Scraper Entrance Mat Prelude™ 231

Product Images

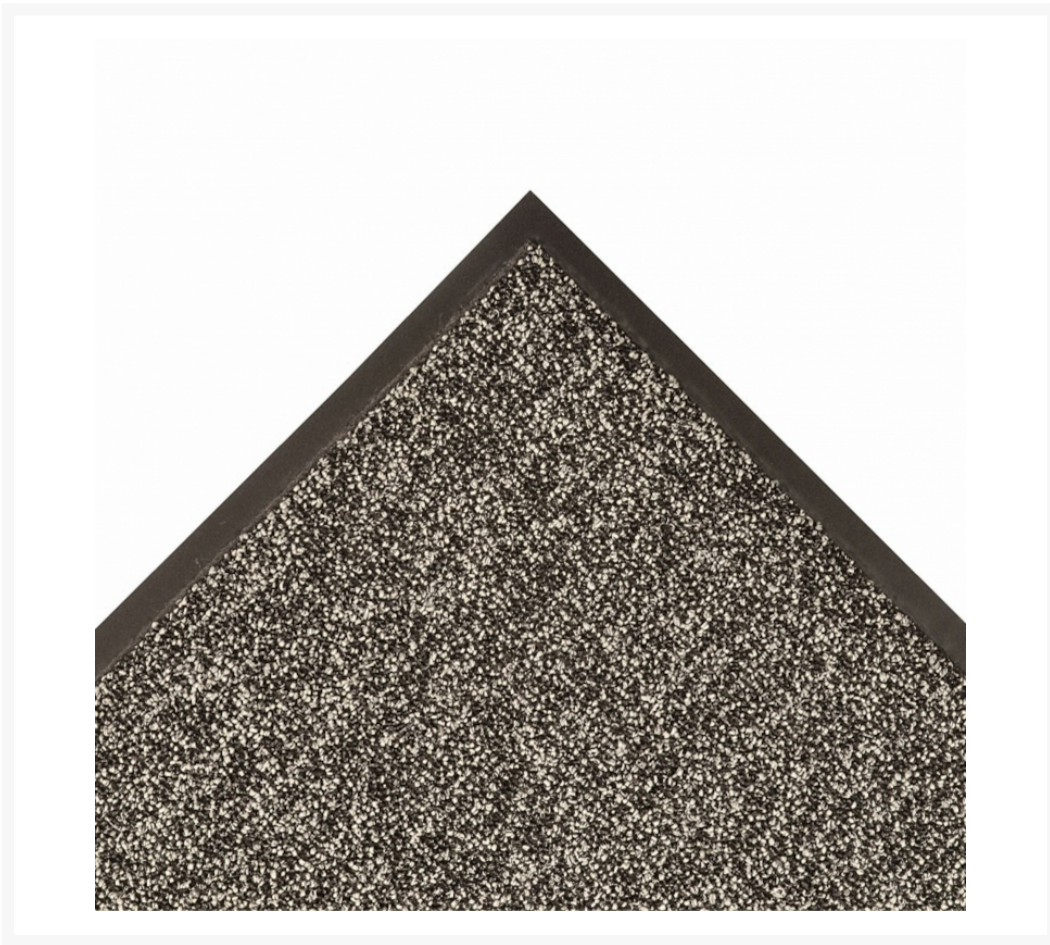

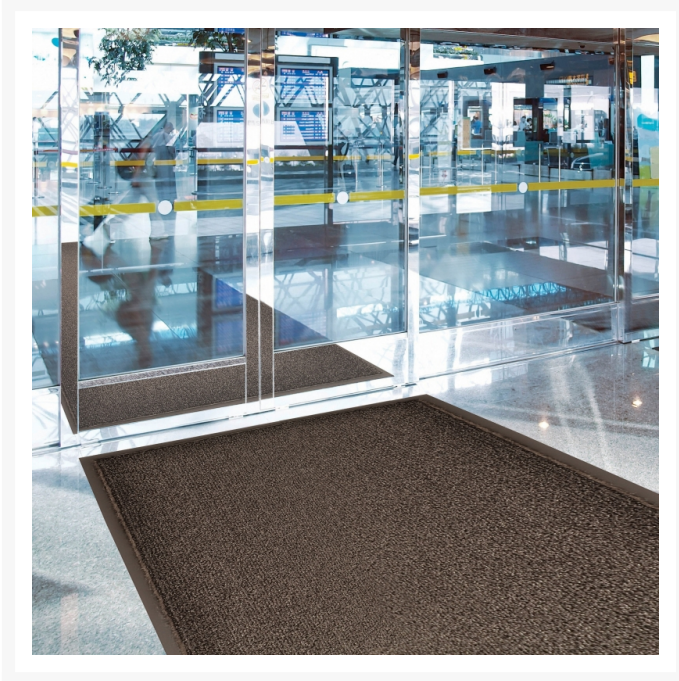

Short Description

- A coarse loop-twisted non-absorbent fiber to scrape heavy debris from foot traffic
- Aggressive fibers resist crushing while entrapping debris and preventing it from entering the facility
- Low profile entrance mat to perform in narrow clearance doorways
- Vinyl backing ensures minimal buckling and mat movement
- Can be used as the first section (Scraping) of the “Stages” entrance mat system

Description

Prelude™ is a scraper mat made up of a coarse loop-twisted non-absorbent fiber that can be placed outside the entrance to begin the removal of dirt and debris from foot traffic. These aggressive fibers resist crushing while entrapping debris and preventing it from entering the facility. This mat can be used as a stand-alone mat, or as the first stage of the coordinated “Stages” entrance matting system. A heavy-weight vinyl non-slip backing ensures minimum movement.

Specifications

Model No	231
Available Colors	Black; Brown; Gray
Overall Thickness	3/8
Roll Sizes	3'x 60'; 4'x 60'; 6'x 60'
Custom Lengths	3', 4' and 6' widths (up to 60' long)
Standard sizes	2'x 3'; 3'x 4'; 3'x 5'; 3'x 6'; 3'x 10'; 4'x 6'; 4'x 8'
Group	Entrance Matting
Environment	Indoor/Outdoor
Recommended Use	For loose lay placement indoors or outdoors
Special Remarks	A total of 15 ft of matting is recommended to prevent 85% of moisture and debris from entering the building.
Surface	Rich Monochrome Colors
Edges	Vinyl borders
Usage Intensity	Medium traffic
Backing	Black vinyl (DOP free)
Process	Tufting
Pile Weight Oz	19
Weight Lbs/sqft	0.6
Fire Rating US	Pass
REACH Compliant	Reach compliant (Registration, Evaluation, Authorization and Restriction of Chemicals).
Dust Control Rating	Better
Water Retention Rating	Better
Crush Resistance Rating	Best
Function Appearance Rating	Best

Product Options

Color:	Black
	Brown
	Gray
Dimensions:	2ft x 3ft
	3ft x 10ft
	3ft x 4ft
	3ft x 5ft
	3ft x 60ft
	3ft x 6ft
	3ft x Specify Length
	4ft x 60ft
	4ft x 6ft
	4ft x 8ft
	4ft x Specify Length
	6ft x 60ft
	6ft x Specify Length