


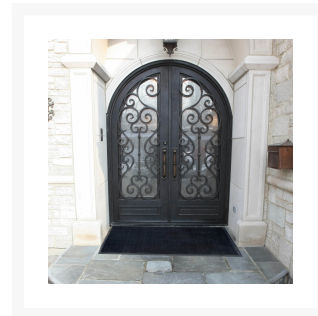


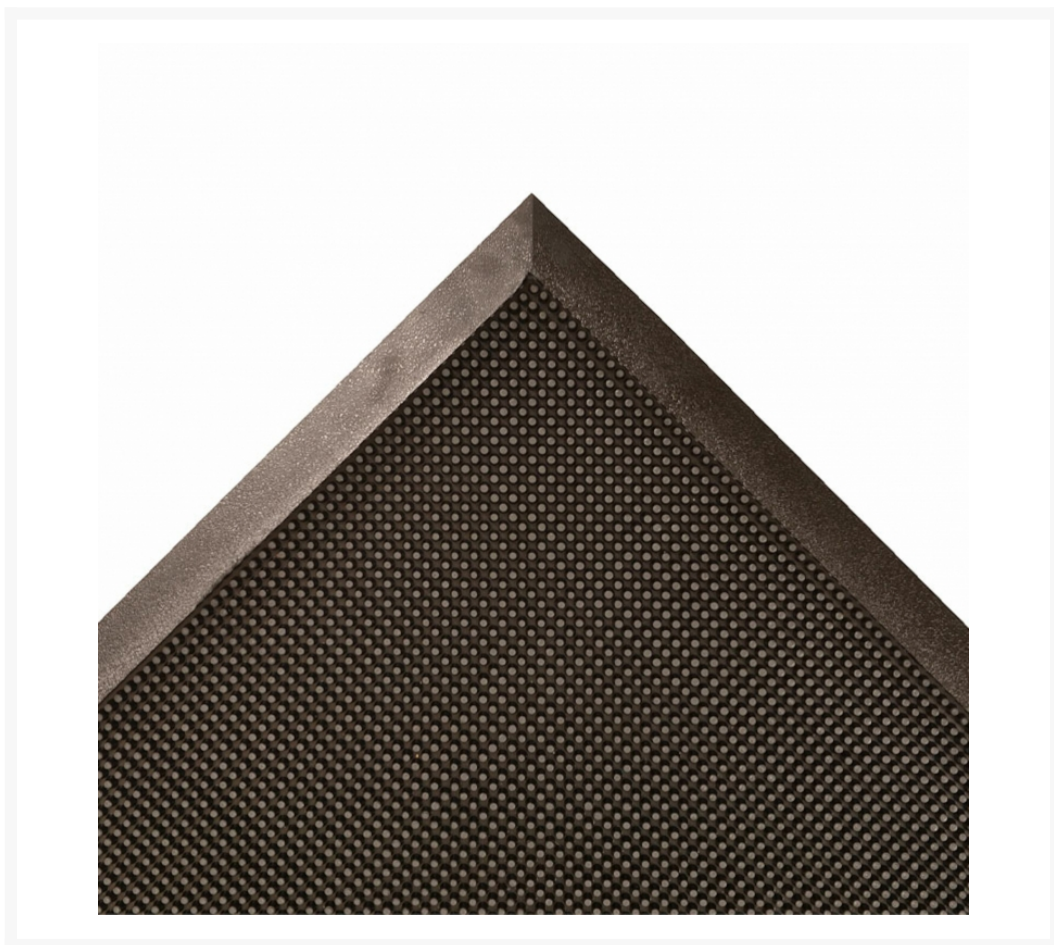

# Scraper Outdoor Brush Mat, Rubber Brush™, 345

## Product Images

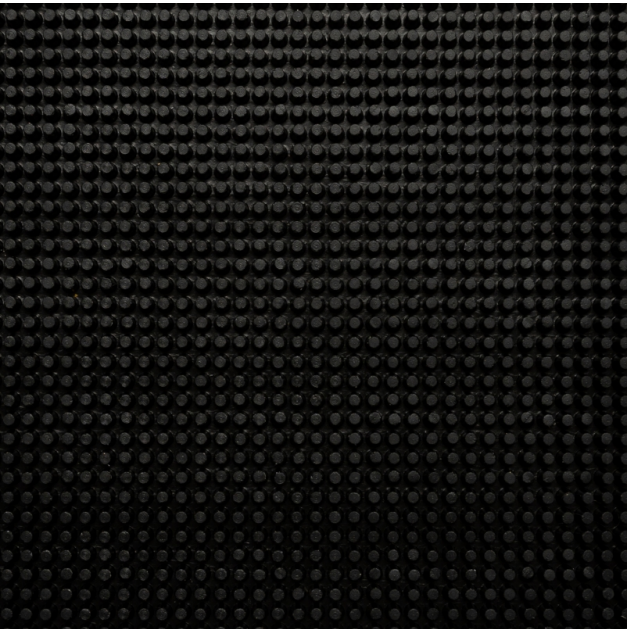

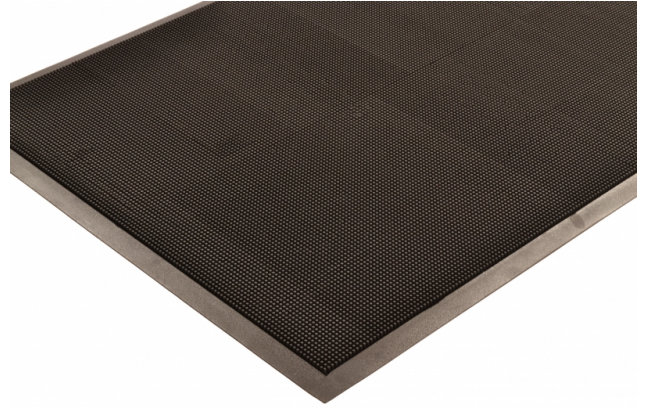

## Short Description

---

- Tough natural rubber remains flexible while withstanding extreme cold
- Thousands of flexible rubber fingers sweep shoes clean
- Suction cups on underside help to minimize mat movement
- Molded beveled edging on all 4 sides creates a retention dam to trap moisture and hides debris
- Heavier duty/better than competition

## Description

---

Rubber Brush™ mats are constructed of tough natural rubber to remain flexible while withstanding extreme cold. Thousands of tough, flexible rubber fingers sweep shoes clean while suction cups on the underside of the mat help to minimize shifting. Due to its durable construction, this outdoor bristle mat is the perfect year round outdoor entrance mat for schools, municipal buildings, plant entrances, and office buildings.

## Specifications

---

Model No	345
Available Colors	Black
Overall Thickness	1/2
Standard sizes	16"x 24"; 28"x 46"
Group	Entrance Matting
Environment	Outdoor
Recommended Use	For placement inside entrances of hotels, shops, department stores, schools, universities, restaurants, supermarkets.
Special Remarks	Be sure to check door clearance.
Surface	Flexible Rubber Bristles
Edges	Beveled rubber borders on all four sides
Usage Intensity	Heavy traffic
Material Specifications	Natural rubber
Process	Compression Molding
Weight Lbs/sqft	2.2
Fire Rating US	Pass
REACH Compliant	Reach compliant (Registration, Evaluation, Authorization and Restriction of Chemicals).
Water Retention Rating	Best
Wear Resistance Rating	Good
Scraping Performance Rating	Best

## Product Options

---

Dimensions:	3ft x 5ft
	3ft x 6ft
	16in x 24in
	24in x 32in
	28in x 46in
	32in x 39in