


16" x 24", Black, Scraper Outdoor Brush Mat, Rubber Brush™, 345

Product Images

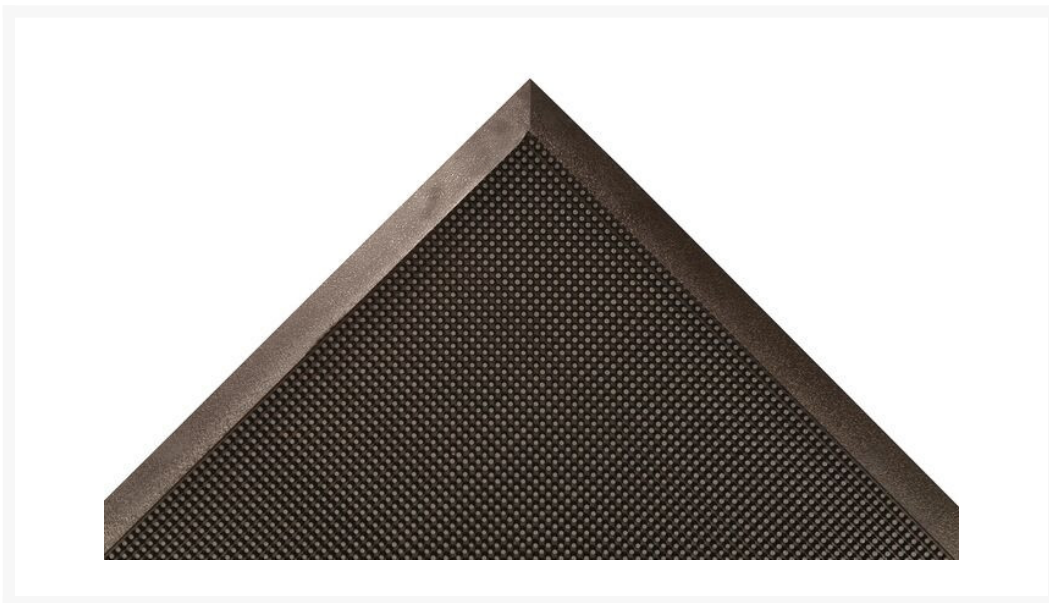

Short Description

- Tough natural rubber remains flexible while withstanding extreme cold
- Thousands of flexible rubber fingers sweep shoes clean
- Suction cups on underside help to minimize mat movement
- Molded beveled edging on all 4 sides creates a retention dam to trap moisture and hides debris
- Heavier duty/better than competition

Description

Rubber Brush™ mats are constructed of tough SBR rubber to remain flexible while withstanding extreme cold. Thousands of tough, flexible rubber fingers sweep shoes clean while suction cups on the underside of the mat help to minimize shifting. Due to its durable construction, this outdoor bristle mat is the perfect year round outdoor entrance mat for schools, municipal buildings, plant entrances, and office buildings.

Specifications

Model No	345S1624BL
Color	Black
Dimensions	16in x 24in
Thickness	1/2in
UPC	662641345010
Brand	NoTrax
Special Price Type	Sale
Available Colors	Black
Standard sizes	16"x24", 24"x32", 28"x46", 32"x39", 36"x60", 36"x72"
Group	Entrance Matting
Environment	Outdoor
Recommended Use	For placement inside entrances of hotels, shops, department stores, schools, universities, restaurants, supermarkets.
Special Remarks	Be sure to check door clearance.
Edges	Beveled rubber borders on all four sides
Usage Intensity	Heavy traffic
Material Specifications	Natural rubber
Surface Detail	Flexible Rubber Bristles
Process	Compression Molding
Pallet Quantity	60
Weight Lbs/sqft	2.2
Thickness Inch	1/2in
Fire Rating US	Pass
REACH Compliant	Reach compliant (Registration, Evaluation, Authorization and Restriction of Chemicals).
Water Retention Rating	Best

Wear Resistance Rating	Good
Scraping Performance Rating	Best