


# 9/16" x 4' x Custom Length, Black, Sof-Tred™ Anti Fatigue Mat, 411

## Product Images

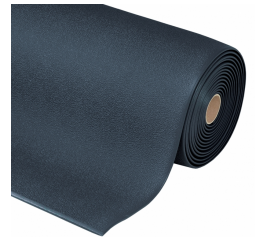



## Short Description

---

- Non-directional pebble-texture embossed mat
- Basic anti-fatigue protection provided
- Closed cell PVC foam relieves leg and back discomfort
- Provides an insulated barrier to cold floors
- Beveled edges on all 4 sides

## Description

---

Sof-Tred™ anti fatigue foam mat has an embossed pebble-texture top surface that enhances the mat's slip resistance while providing increased basic worker fatigue relief. The PVC closed cell foam construction relieves leg and back discomfort while providing a barrier to cold floors. Sof-Tred™ is intended for applications where basic anti-fatigue relief is required at a low cost.

## Specifications

|                         |                                                                                                                             |
|-------------------------|-----------------------------------------------------------------------------------------------------------------------------|
| Model No                | 411C0448BL                                                                                                                  |
| Color                   | Black                                                                                                                       |
| Dimensions              | 4ft x Specify Length                                                                                                        |
| Thickness               | 9/16in                                                                                                                      |
| UPC                     | 662641661363                                                                                                                |
| Brand                   | NoTrax                                                                                                                      |
| Available Colors        | Black; Black/Yellow; Blue; Gray                                                                                             |
| Roll Sizes              | 2'x60', 3'x60', 4'x60', 6'x60'                                                                                              |
| Custom Lengths          | 2', 3' and 4' widths (up to 60' long)                                                                                       |
| Standard sizes          | 2'x3', 3'x5', 3'x12'                                                                                                        |
| Group                   | Ergonomic, Anti-fatigue & Safety Matting                                                                                    |
| Environment             | Dry Areas                                                                                                                   |
| Special Characteristics | Free of DOP, free of DMF, free of ozone depleting substances, free of silicone and free of heavy metals                     |
| Recommended Use         | For placement in manufacturing plants, assembly lines, picking, packing and logistics warehouses, individual work stations. |
| Special Remarks         | Where basic anti-fatigue and anti-slip properties are needed at a low cost                                                  |
| Edges                   | Beveled edges on all sides                                                                                                  |
| Usage Intensity         | Light duty                                                                                                                  |
| Custom Description      | Available in stock and rolls sizes and in custom lengths. Available colors in black/yellow and black.                       |
| Material Specifications | Closed Cell Polyvinylchloride                                                                                               |
| Surface Detail          | Structured Pebble Pattern                                                                                                   |
| Backing                 | Closed Cell Polyvinylchloride                                                                                               |
| Process                 | Foaming                                                                                                                     |
| Weight Lbs/sqft         | 0.53                                                                                                                        |

|                        |                                                                                         |
|------------------------|-----------------------------------------------------------------------------------------|
| Thickness Inch         | 9/16in                                                                                  |
| Fire Rating US         | Pass                                                                                    |
| REACH Compliant        | Reach compliant (Registration, Evaluation, Authorization and Restriction of Chemicals). |
| Anti-Fatigue Rating    | Good                                                                                    |
| Slip Resistance Rating | Good                                                                                    |
| Wear Resistance Rating | Good                                                                                    |