
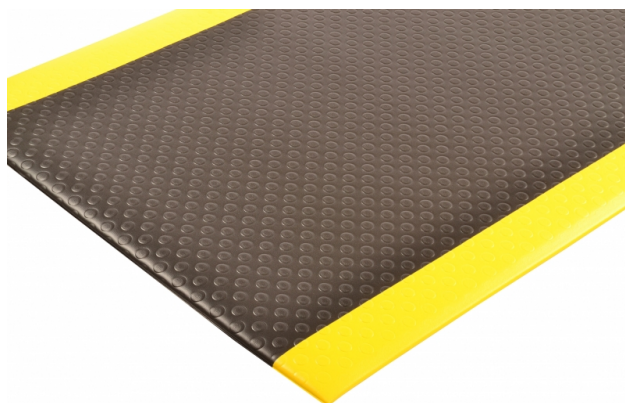
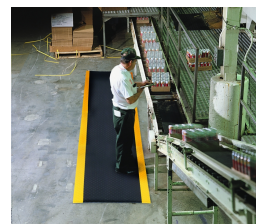
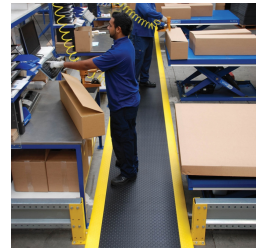


# 4' x Custom Length, Black-Yellow, Bubble Soft-Tred™ with Dyna-Shield® Anti Fatigue Mat, 417

## Product Images

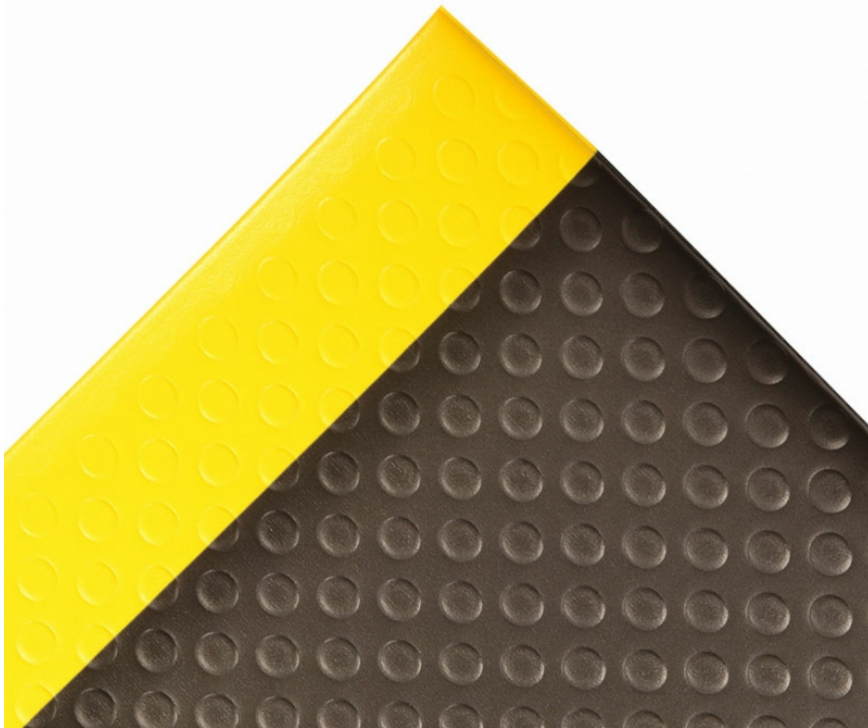

## Short Description

---

- Non-directional bubble textured embossed mat maximizes worker comfort
- PVC foam provides added cushioning comfort, relieves leg and back discomfort
- Exclusive Dyna-Shield® top surface manufactured directly into the mat for long lasting wear
- Superior tear resistance and tensile strength
- Beveled edges on all 4 sides

## Description

---

Bubble Sof-Tred™ with Dyan-Shield® is an anti-fatigue mat that is designed to provide traction with a unique bubble embossed top surface that allows for sure footing and is easy to sweep clean. The NoTrax® exclusive Dyna-Shield® PVC foam is manufactured with a tough protective barrier top layer that provides long lasting wear and outperforms the competition in tear resistance and tensile strength. Dyna-Shield® products are more resistant to wear than traditional sponge matting. Designed for use in medium duty dry work areas.

## Specifications

|                         |                                                                                                                                                                                           |
|-------------------------|-------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Model No                | 417C0048BY                                                                                                                                                                                |
| Color                   | Black/Yellow                                                                                                                                                                              |
| Dimensions              | 4ft x Specify Length                                                                                                                                                                      |
| Thickness               | 1/2in                                                                                                                                                                                     |
| UPC                     | 662641741058                                                                                                                                                                              |
| Brand                   | NoTrax                                                                                                                                                                                    |
| Available Colors        | Black/Yellow; Gray                                                                                                                                                                        |
| Roll Sizes              | 2'x60', 3'x60', 4'x60'                                                                                                                                                                    |
| Custom Lengths          | 2', 3' and 4' widths (up to 60' long)                                                                                                                                                     |
| Standard sizes          | 2'x3', 2'x6', 3'x4', 3'x5', 3'x6', 3'x12'                                                                                                                                                 |
| Group                   | Ergonomic, Anti-fatigue & Safety Matting                                                                                                                                                  |
| Environment             | Dry Areas                                                                                                                                                                                 |
| Special Characteristics | Free of DOP, free of DMF, free of ozone depleting substances, free of silicone and free of heavy metals                                                                                   |
| Recommended Use         | For placement in manufacturing plants, assembly lines, picking, packing and logistics warehouses, individual work stations.                                                               |
| Special Remarks         | With Dyna-Shield® - The only mid-priced/high performance anti-fatigue sponge mat available with durability approaching that of competitive "laminated" mats. Extends service life by 50%. |
| Edges                   | Beveled edges on all sides                                                                                                                                                                |
| Usage Intensity         | Medium duty                                                                                                                                                                               |
| Custom Description      | Available in stock and rolls sizes and in custom lengths. Available colors in black/yellow and black                                                                                      |
| Cleaning Remark         | Sweep regularly or dry mop the surface and the back of the mat. The surface can be damp-mopped with a mild soap/detergent.                                                                |
| Material Specifications | Closed Cell Polyvinylchloride                                                                                                                                                             |
| Surface Detail          | Industrial Bubble Pattern                                                                                                                                                                 |
| Backing                 | Closed Cell Polyvinylchloride                                                                                                                                                             |

|                        |                                                                                         |
|------------------------|-----------------------------------------------------------------------------------------|
| Process                | Foaming                                                                                 |
| Weight Lbs/sqft        | 0.83                                                                                    |
| Thickness Inch         | 1/2in                                                                                   |
| Fire Rating US         | Pass                                                                                    |
| REACH Compliant        | Reach compliant (Registration, Evaluation, Authorization and Restriction of Chemicals). |
| Anti-Fatigue Rating    | Better                                                                                  |
| Slip Resistance Rating | Better                                                                                  |
| Wear Resistance Rating | Better                                                                                  |