

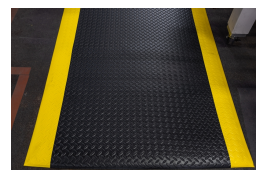
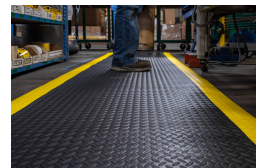


2' x Custom Length, Black-Yellow, Diamond Sof-Tred[™] with Dyna-Shield[®] Anti Fatigue Mat, 419

Product Images

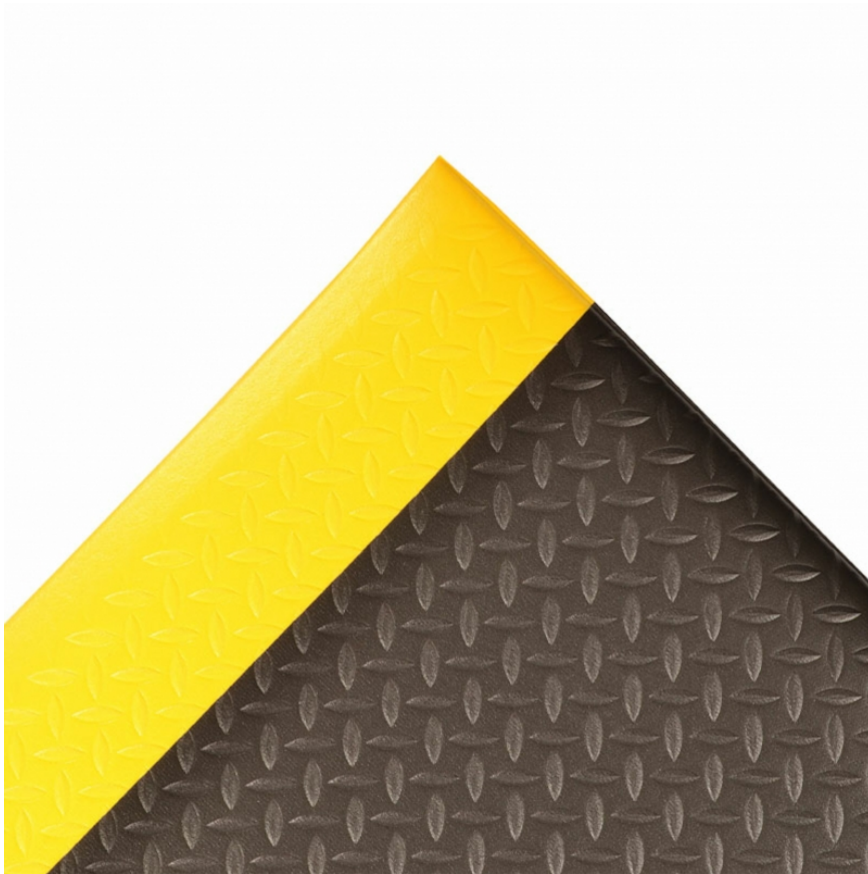

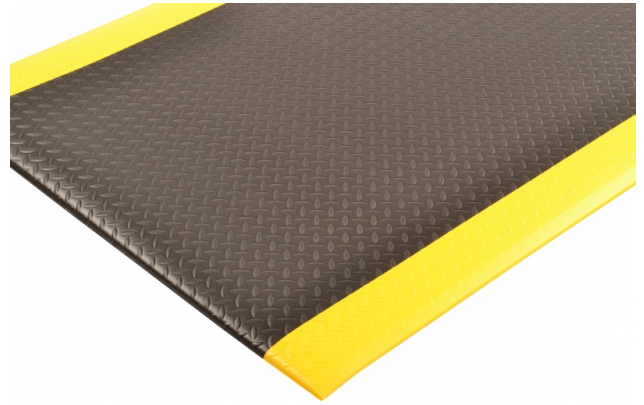

Short Description

- Non-directional diamond plate textured embossed mat maximizes worker comfort
- PVC foam provides added cushioning comfort, relieves leg and back discomfort
- Exclusive Dyna-Shield® top surface manufactured directly into the mat for long lasting wear
- Superior tear resistance and tensile strength
- Beveled edges on all 4 sides

Description

Diamond Sof-Tred™ with Dyna-Shield® is an anti-fatigue mat that is designed to provide traction with its non-directional diamond plate embossed top surface that allows for sure footing and is easy to sweep clean. The NoTrax® exclusive Dyna-Shield® PVC foam is manufactured with a tough protective barrier top layer that provides long lasting wear and outperforms the competition in tear resistance and tensile strength. Dyna-Shield® products are more resistant to wear than traditional sponge matting. Designed for use in medium duty dry work areas.

Specifications

Model No	419C0024BY
Color	Black/Yellow
Dimensions	2ft x Specify Length
Thickness	1/2in
UPC	662641669765
Brand	NoTrax
Available Colors	Black; Black/Yellow; Gray
Roll Sizes	2'x60', 3'x60', 4'x60'
Custom Lengths	2', 3' and 4' widths (up to 60' long)
Standard sizes	2'x3', 2'x6', 3'x4', 3'x5', 3'x6', 3'x12'
Group	Ergonomic, Anti-fatigue & Safety Matting
Environment	Dry Areas
Special Characteristics	Free of DOP, free of DMF, free of ozone depleting substances, free of silicone and free of heavy metals
Recommended Use	For placement in manufacturing plants, assembly lines, picking, packing and logistics warehouses, individual work stations.
Special Remarks	With Dyna-Shield® - The only mid-priced/high performance anti-fatigue sponge mat available with durability approaching that of competitive "laminated" mats. Extends service life by 50%.
Edges	Beveled edges on all sides
Usage Intensity	Medium duty
Custom Description	Available in stock and rolls sizes and in custom lengths. Available colors in black/yellow and black
Cleaning Remark	Sweep regularly or dry mop the surface and the back of the mat. The surface can be damp-mopped with a mild soap/detergent.
Material Specifications	Closed Cell Polyvinylchloride
Surface Detail	Raised Diamond Pattern
Backing	Closed Cell Polyvinylchloride

Process	Foaming
Weight Lbs/sqft	0.83
Thickness Inch	1/2in
Fire Rating US	Pass
REACH Compliant	Reach compliant (Registration, Evaluation, Authorization and Restriction of Chemicals).
Anti-Fatigue Rating	Better
Slip Resistance Rating	Better
Wear Resistance Rating	Better