


---

## 3' x Custom Length, Black, Cushion-Dek™ Anti Slip Mat, 420

### Product Images

---

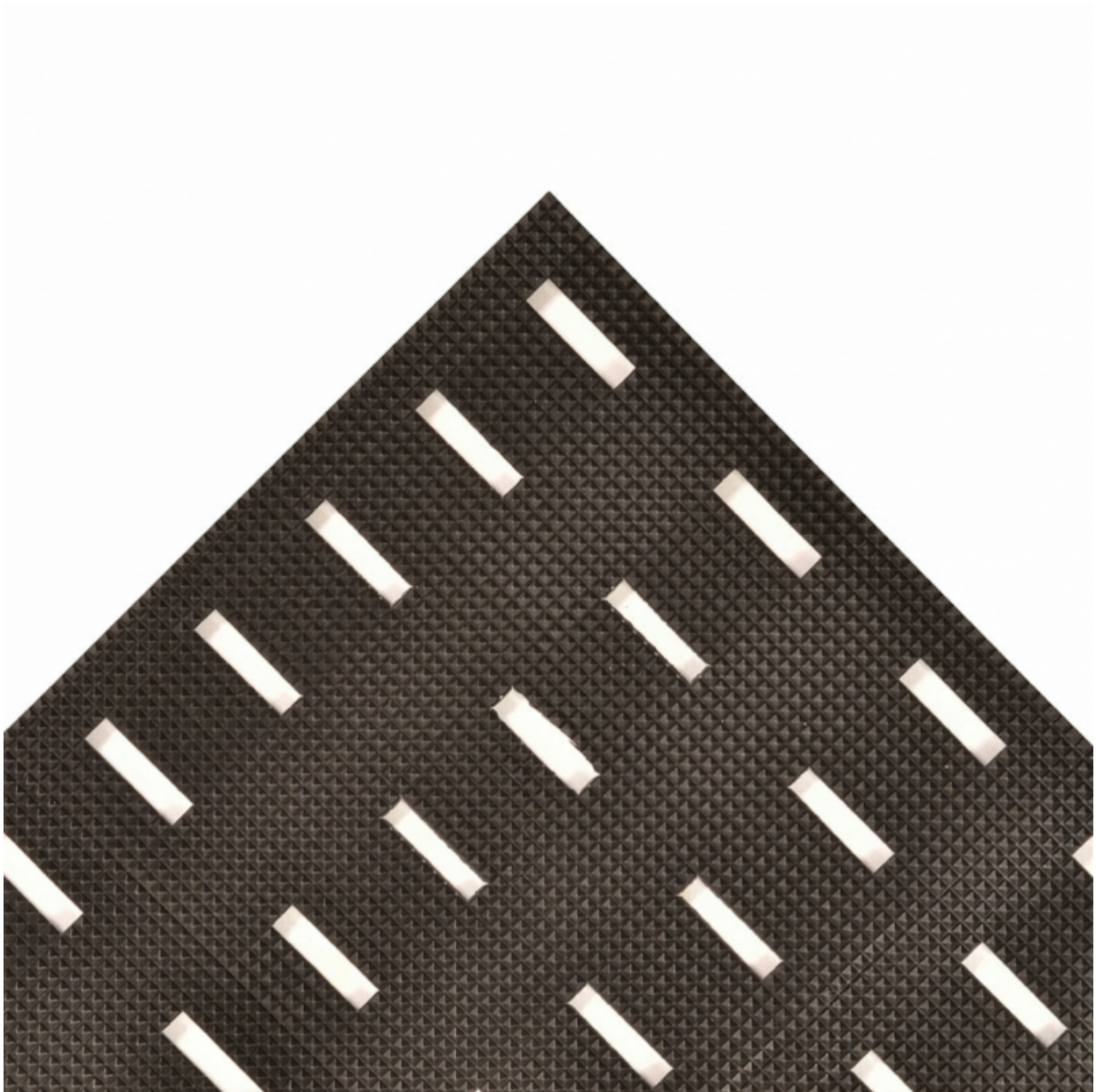

## Short Description

---

- Tough PVC compound molded with a raised pyramid design to enhance traction
- Made from 100% recycled PVC
- Drainage system for use in wet areas
- Slotted perforations (1/2" wide x 1-7/8" long) allow for moisture to escape worker platform
- Studded bottom surface raises mat and allows for channeling of moisture and continuous aeration

## Description

---

Cushion-Dek™ is made from a tough PVC compound molded with a raised pyramid design to enhance traction. Slotted perforations allow for moisture to drain from the worker platform in wet environments. A studded bottom surface raises the mat and allows for channeling of moisture.

## Specifications

|                         |                                                                                                                                       |
|-------------------------|---------------------------------------------------------------------------------------------------------------------------------------|
| Model No                | 420C0036BL                                                                                                                            |
| Color                   | Black                                                                                                                                 |
| Dimensions              | 3ft x Specify Length                                                                                                                  |
| Thickness               | 7/16in                                                                                                                                |
| UPC                     | 662641640078                                                                                                                          |
| Brand                   | NoTrax                                                                                                                                |
| Available Colors        | Black                                                                                                                                 |
| Roll Sizes              | 2'x30', 3'x30', 4'x30'                                                                                                                |
| Custom Lengths          | 2', 3' and 4' widths (up to 30' long)                                                                                                 |
| Standard sizes          | 2'x3', 2'x6', 3'x4', 3'x6', 3'x10', 4'x6', 4'x8'                                                                                      |
| Group                   | Ergonomic, Anti-fatigue & Safety Matting                                                                                              |
| Environment             | Wet/Dry and Oily Areas                                                                                                                |
| Special Characteristics | Free of DOP, free of DMF, free of ozone depleting substances, free of silicone and free of heavy metals   Resistant to most chemicals |
| Recommended Use         | For placement in manufacturing plants, assembly lines, picking, packing and logistics warehouses, individual work stations.           |
| Special Remarks         | Factory-assembled custom configurations available                                                                                     |
| Edges                   | No borders                                                                                                                            |
| Usage Intensity         | Heavy duty                                                                                                                            |
| Material Specifications | PVC (DOP free)                                                                                                                        |
| Surface Detail          | Raised Pyramid Configuration                                                                                                          |
| Process                 | Injection Molding                                                                                                                     |
| Weight Lbs/sqft         | 1.3                                                                                                                                   |
| Thickness Inch          | 7/16in                                                                                                                                |
| Fire Rating US          | Pass                                                                                                                                  |

|                        |                                                                                         |
|------------------------|-----------------------------------------------------------------------------------------|
| REACH Compliant        | Reach compliant (Registration, Evaluation, Authorization and Restriction of Chemicals). |
| Anti-Fatigue Rating    | Better                                                                                  |
| Slip Resistance Rating | Better                                                                                  |
| Wear Resistance Rating | Better                                                                                  |

## Prop 65

---

**⚠️WARNING:** This product can expose you to chemicals including di-2-ethylhexyl phthalate and/or diisononyl phthalate which is known to the State of California to cause cancer, birth defects or reproductive harm. For more information, visit [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).