

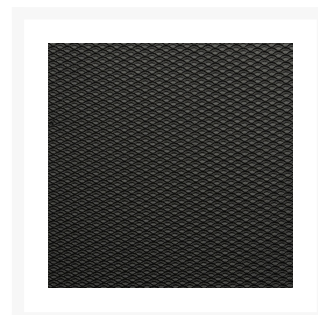
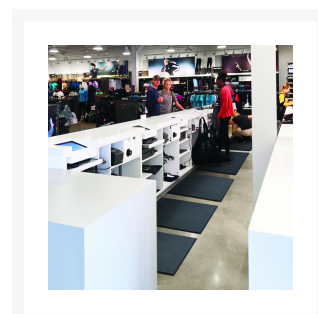
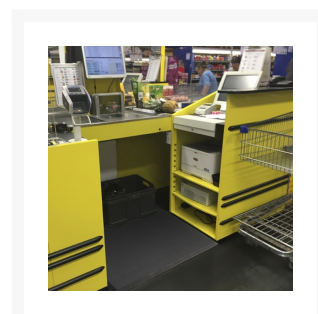


Standing Desk Mat Superfoam™ Revive RS 425

Product Images

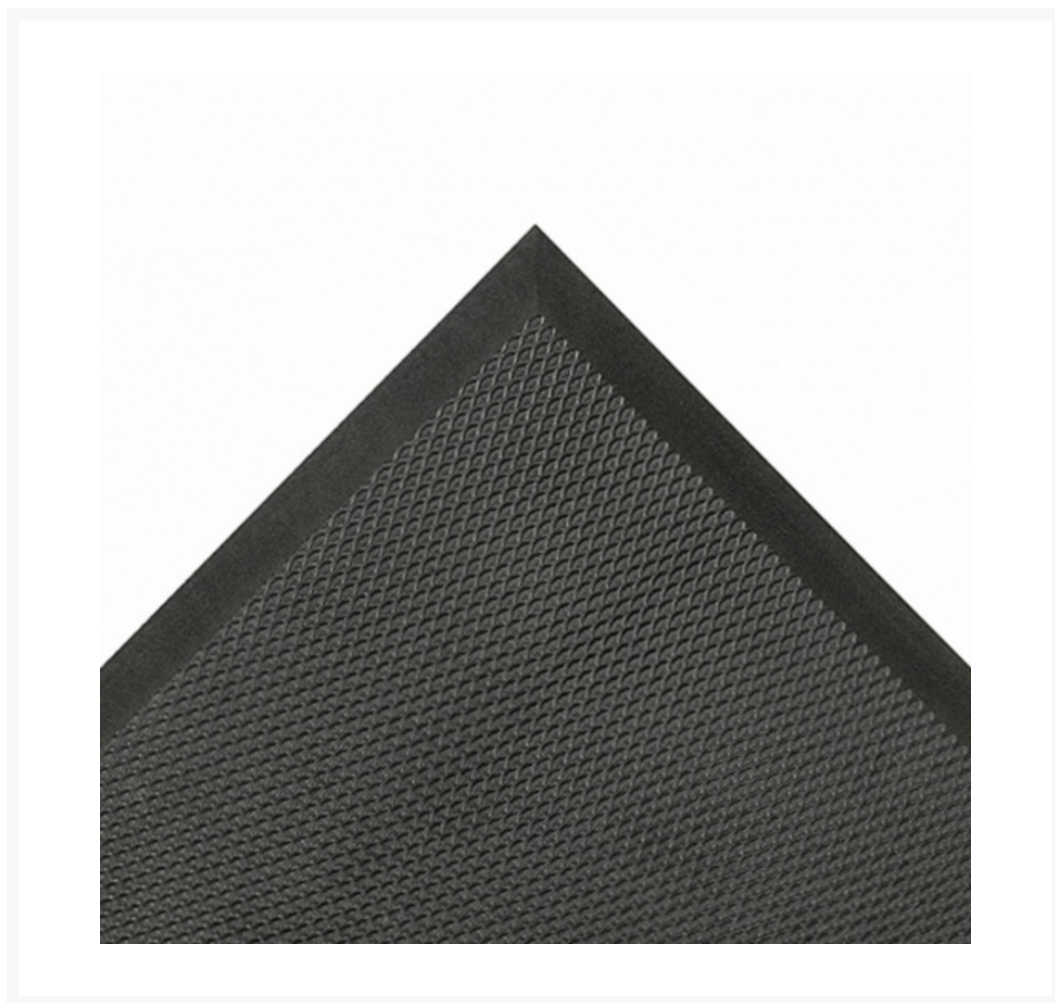

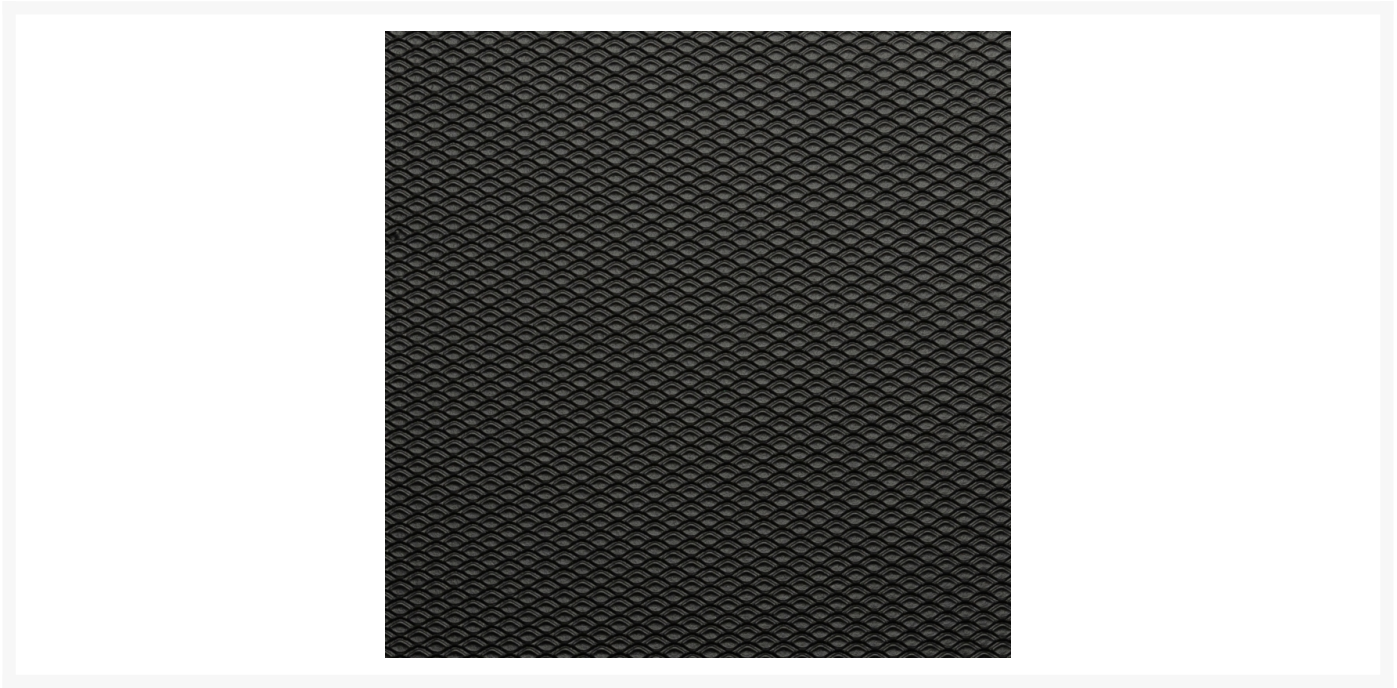

Short Description

- Ideal standing mat for desk in a home office or as a workstation mat in industrial environments. Safe for chair stools and high heels
- Closed cell rubber gel foam blend does not absorb liquids and mildew-proof
- Highly resistant to grease, oils and animal & vegetable fats
- Durable, lightweight rubberized gel foam is easy to pick up and move
- Ergonomically designed standup mat that provides high level of rebound without bottoming out
- Non-allergenic, silicone-free compound. Anti-bacterial.
- Beveled edges on all 4 sides

Description

Superfoam™ Revive RS standing mat for standing desk is a durable rubberized gel foam mat designed for extreme ergonomic comfort. Made from a completely closed cell foam, Superfoam™ Revive RS stand up desk mat does not absorb liquids and is highly resistant to grease, oils and animal and vegetable fats. Super soft upper layer and a dense under layer with mildew-proof antibacterial formulation makes the mat itself more hygienic and long lasting. This anti-fatigue mat for standing desks is ideal for workers standing for long periods of time, bathrooms or kitchens. This is the best standing desk mat, perfect for home office and durable enough for industrial use.

Model No	425
Available Colors	Black
Overall Thickness	3/4
Standard sizes	20"x 24"; 36"x 40"
Group	Ergonomic, Anti-fatigue & Safety Matting
Environment	Wet/Dry and Oily Areas
Special Characteristics	Free of DOP, free of DMF, free of ozone depleting substances, free of silicone and free of heavy metals Resistant to most industrial fluids and chemicals
Recommended Use	Ideal for stationary standing workstations, sit-stand desks, packing stations, office environments, reception areas, wait stations, service counters, cashiers
Special Remarks	Extremely light-weight, designed for ease of handling in areas where mats are regularly moved for cleaning
Surface	Raised Grid Pattern
Edges	Beveled edges on all sides
Usage Intensity	Medium duty
Process	Foaming
Weight Lbs/sqft	1.3
Fire Rating US	Pass
REACH Compliant	Reach compliant (Registration, Evaluation, Authorization and Restriction of Chemicals).
Anti-Fatigue Rating	Superior
Slip Resistance Rating	Best
Wear Resistance Rating	Best

Specifications

Product Options

Dimensions:	2ft x 6ft
	3ft x 5ft
	20in x 24in
	24in x 40in
	36in x 40in