



Bubble Top Anti-Fatigue Mat Comfort-Eze™ 447

Product Images

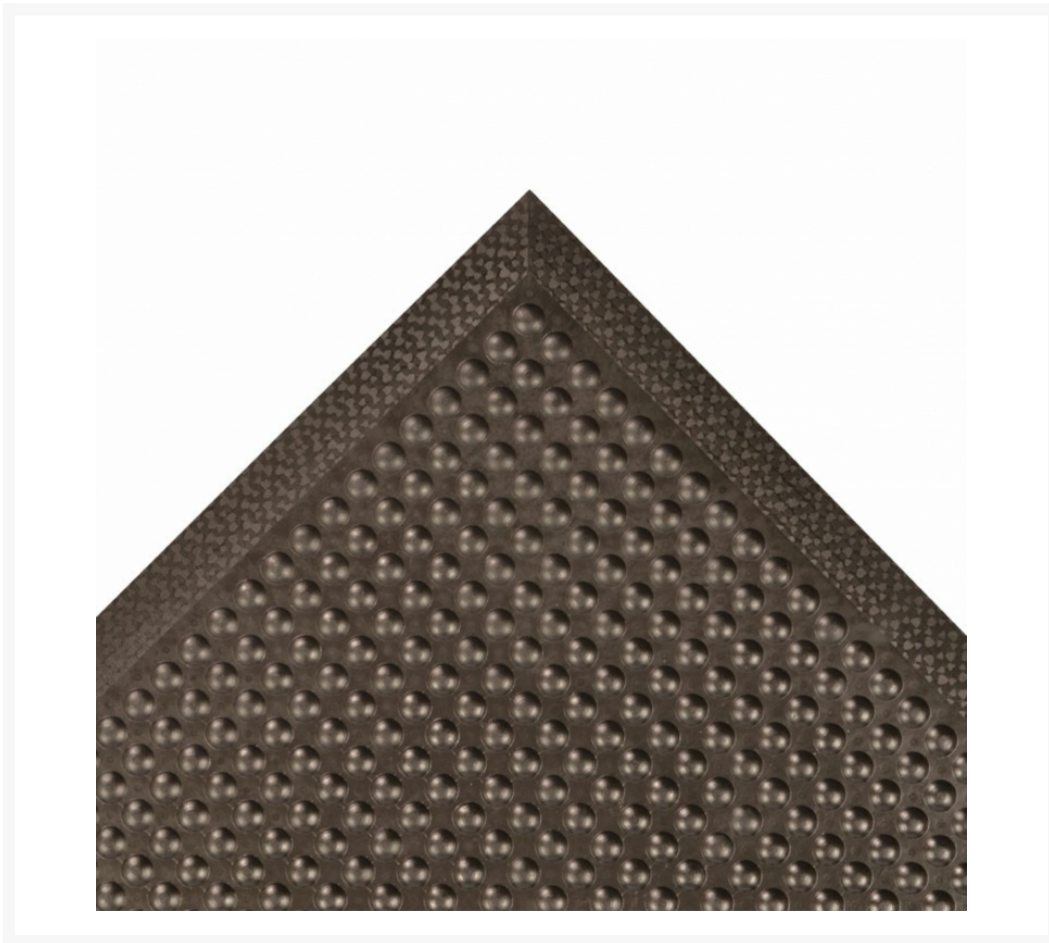

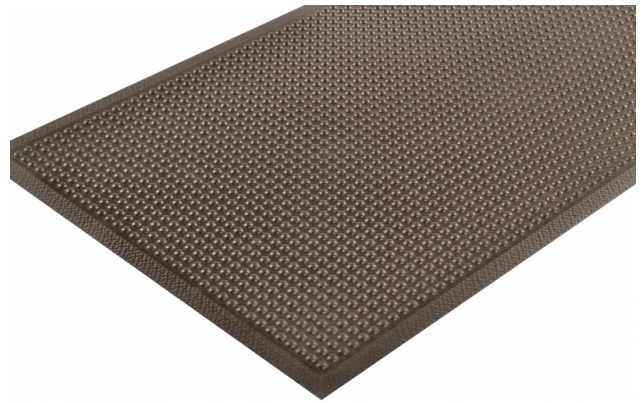

Short Description

- Long-lasting rubber compound
- Rubber molded, air-pocket underside anti-fatigue mat
- Bubbles are molded on an offset on the top and bottom of the mat to maximize flex and create air flow, all to enhance the ergonomic benefit
- Durable rubber top surface easy to wipe clean using most cleaners and disinfectants
- Beveled edges on all 4 sides

Description

Constructed with a unique solid rubber design, Comfort-Eze™ stimulates worker comfort and promotes product longevity. Offset bubbles on both the top and bottom of the mat provides flex and creates airflow resulting in maximum comfort for workers required to be on their feet for long periods of time. Competitive products feature only a flat or hollowed bottom which reduces the comfort of the mat. Although intended for use in dry environments, the top surface design is easy to wipe clean and the durable rubber compound is highly resistant to many cleaners and disinfectants so occasional spills can be cleaned up quickly and easily. Molded beveled edges on all four sides eliminates trip hazards by allowing for easy access onto and off the mat.

Specifications

Model No	447
Available Colors	Black
Overall Thickness	3/8
Standard sizes	2'x 3'; 30"x 10'; 30"x 60"
Group	Ergonomic, Anti-fatigue & Safety Matting
Environment	Dry Areas
Special Characteristics	Free of DOP, free of DMF, free of ozone depleting substances, free of silicone and free of heavy metals
Recommended Use	For placement in manufacturing plants, assembly lines, picking, packing and logistics warehouses, individual work stations.
Special Remarks	Lightweight, easy to move to clean the floor underneath
Surface	Industrial Bubble Pattern
Edges	Molded beveled edges on all sides
Usage Intensity	Medium duty
Process	Compression Molding
Weight Lbs/sqft	1.3
Fire Rating US	Pass
REACH Compliant	Reach compliant (Registration, Evaluation, Authorization and Restriction of Chemicals).
Anti-Fatigue Rating	Better
Slip Resistance Rating	Better
Wear Resistance Rating	Better

Product Options

Dimensions:	2.5ft x 10ft
-------------	--------------

	2.5ft x 5ft
--	-------------

	2ft x 3ft
--	-----------