


# 3' x Custom Length, Black-Yellow, Diamond-Tuff™ Vinyl Laminate Anti Fatigue Mat, 509

## Product Images

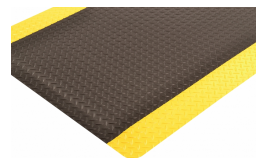

## Short Description

- Durable diamond pattern vinyl laminate top surface for added traction
- Dense closed cell PVC foam base provides added cushioning comfort
- Beveled edges on all 4 sides

## Description

---

Diamond-Tuff™ is a durable diamond anti-fatigue/anti-slip mat with a vinyl diamond plate top surface that provides sure footing and a foam base to provide the ultimate relief for leg and back discomfort in work applications where standing occurs for long periods of time. Diamond-Tuff™ is available in both workstation sizes and full rolls for applications that require a longer mat such as assembly lines. The non-directional diamond plate top surface is easy to sweep or damp mop clean. The sloped beveled edges reduce tripping hazards and allow easy access on and off the mat.

## Specifications

|                         |                                                                                                                             |
|-------------------------|-----------------------------------------------------------------------------------------------------------------------------|
| Model No                | 509C0036YB                                                                                                                  |
| Color                   | Black/Yellow                                                                                                                |
| Dimensions              | 3ft x Specify Length                                                                                                        |
| Thickness               | 9/16in                                                                                                                      |
| UPC                     | 662641820937                                                                                                                |
| Brand                   | NoTrax                                                                                                                      |
| Available Colors        | Black; Black/Yellow                                                                                                         |
| Overall Thickness       | 9/16                                                                                                                        |
| Roll Sizes              | 2'x 75'; 3'x 75'; 4'x 75'; 5'x 75'                                                                                          |
| Standard sizes          | 2'x 3'; 3'x 5'; 3'x 12'                                                                                                     |
| Group                   | Ergonomic, Anti-fatigue & Safety Matting                                                                                    |
| Environment             | Dry Areas                                                                                                                   |
| Special Characteristics | Free of DMF, free of ozone depleting substances, free of silicone and free of heavy metals                                  |
| Recommended Use         | For placement in manufacturing plants, assembly lines, picking, packing and logistics warehouses, individual work stations. |
| Special Remarks         | The Diamond-Tuff™ series comes in 9/16" and a full 1" versions and allow you to select your level of comfort.               |
| Edges                   | Beveled edges on all sides                                                                                                  |
| Usage Intensity         | Medium duty                                                                                                                 |
| Installation            | No installation required                                                                                                    |
| Material Specifications | PVC                                                                                                                         |
| Surface Detail          | Industrial Diamond Plate                                                                                                    |
| Backing                 | Closed Cell Polyvinylchloride                                                                                               |
| Process                 | Lamination                                                                                                                  |
| Weight Lbs/sqft         | 1.1                                                                                                                         |
| Thickness Inch          | 9/16in                                                                                                                      |

|                        |        |
|------------------------|--------|
| Fire Rating US         | Pass   |
| Anti-Fatigue Rating    | Better |
| Slip Resistance Rating | Best   |
| Wear Resistance Rating | Better |

## Prop 65

---

**⚠️WARNING:** This product can expose you to chemicals including di-2-ethylhexyl phthalate and/or diisononyl phthalate which is known to the State of California to cause cancer, birth defects or reproductive harm. For more information, visit [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).