


524S4248GN

Product Images

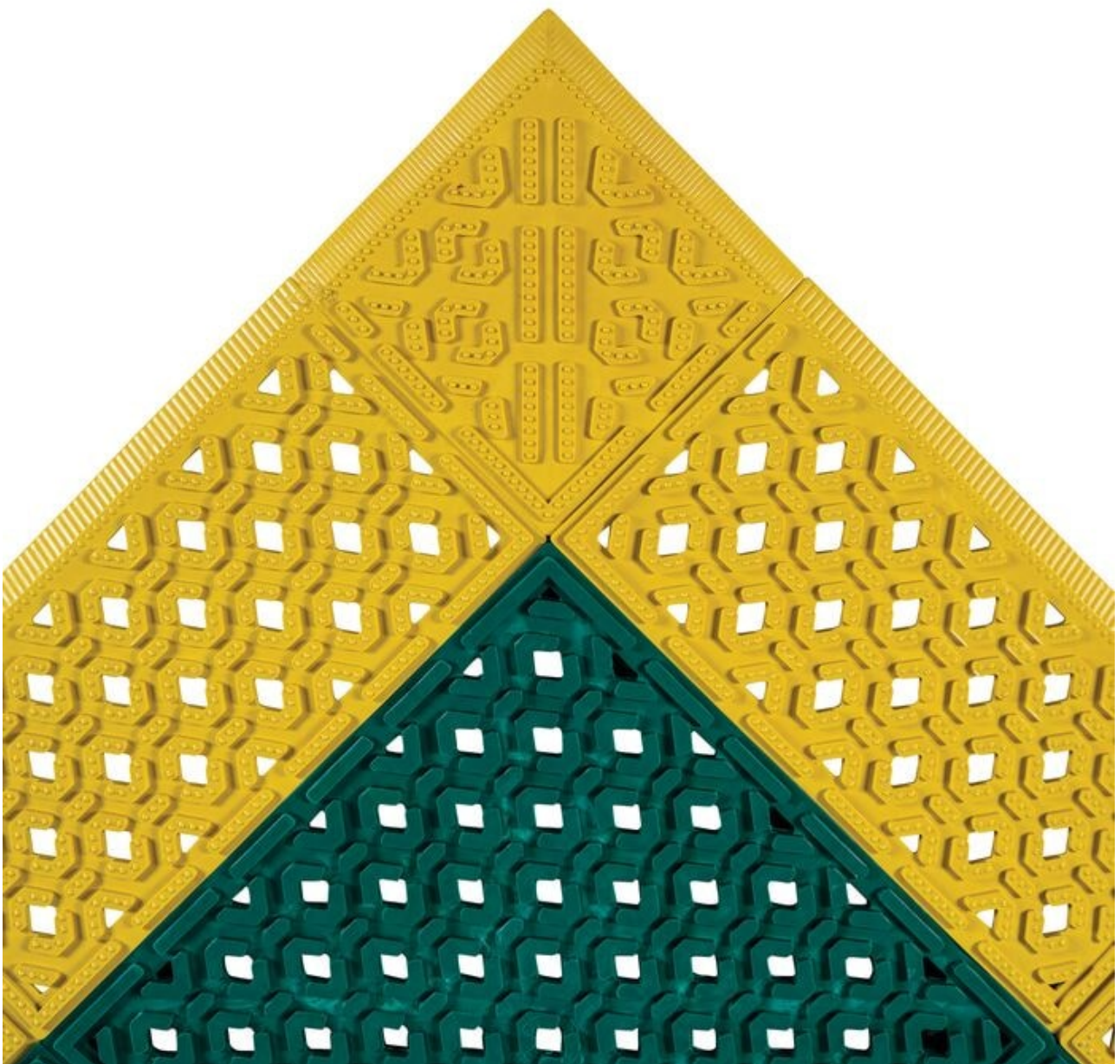

Specifications

Model No	524S4248GN
Color	Green
Dimensions	3.5ft x 4ft
Thickness	7/8in
UPC	662641952461
Brand	NoTrax
Available Colors	Green/Yellow
Overall Thickness	7/8
Standard sizes	30" x 36"; 30" x 48"; 36" x 42"; 42" x 48"; 48" x 54"
Group	Ergonomic, Anti-fatigue & Safety Matting
Environment	Wet Areas
Recommended Use	For placement in in front of emergency response stations.
Special Remarks	Factory-assembled custom configurations available - Call Customer Service for more information (800) 621-2802
Edges	Beveled edges on all sides
Usage Intensity	Heavy duty
Material Specifications	PVC
Surface Detail	Perforated Drainage Pattern
Process	Injection Molding
Weight Lbs/sqft	1.9
Thickness Inch	7/8in
Fire Rating US	Pass
REACH Compliant	Reach compliant (Registration, Evaluation, Authorization and Restriction of Chemicals).
Anti-Fatigue Rating	Best
Slip Resistance Rating	Best

Prop 65

⚠️WARNING: This product can expose you to chemicals including di-2-ethylhexyl phthalate and/or diisononyl phthalate which is known to the State of California to cause cancer, birth defects or reproductive harm. For more information, visit www.P65Warnings.ca.gov.