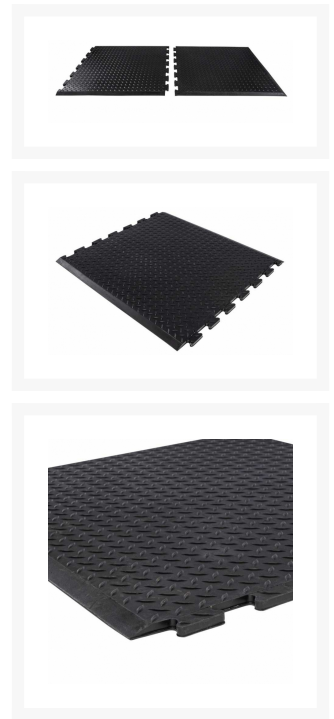
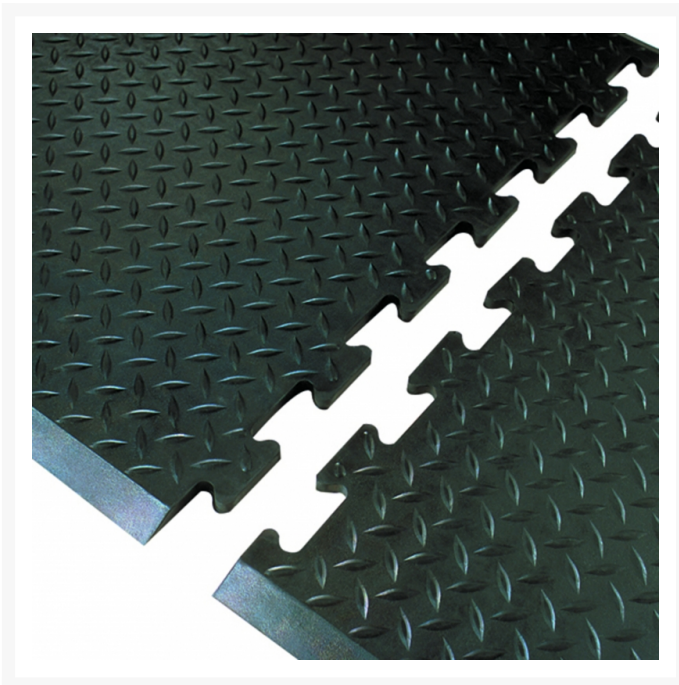

Rubber Traction Mats Diamond Top Interlock™ 545

Product Images





Short Description

- Solid rubber construction
- Diamond-plate top surface pattern for added traction
- A sturdy waffle support system on the underside for maximum worker comfort
- Available in three versions: * "Single" beveled borders on all 4 sides * "End" interlocking teeth on one end * "Center" interlocking teeth on both ends

Description

Diamond Top Interlock™ features a rubber diamond plate top surface for traction, and a sturdy waffle support system on the underside for maximum comfort. Offered as a stand alone mat, or as an interlocking continuous length, this mat is perfect for assembly lines, welding areas, picking lines, and other heavy duty dry work areas. Diamond Top Interlock™ works well in wet or dry environments where long runs of anti-fatigue matting are needed.

Specifications

Model No	545
Available Colors	Black
Overall Thickness	1/2
Standard sizes	28"x 31"; 36"x 31"
Group	Ergonomic, Anti-fatigue & Safety Matting
Environment	Dry Areas
Recommended Use	For placement in manufacturing plants, assembly lines, picking, packing and logistics warehouses, individual work stations.
Special Remarks	Can only make custom lengths, not widths. Store extra sections on-site so sections damaged by forklift, etc. Can quickly and easily be replaced.
Surface	Raised Diamond Pattern
Edges	Molded beveled edges on all sides
Usage Intensity	Medium duty
Material Specifications	Natural rubber
Process	Compression Molding
Weight Lbs/sqft	1.6
Fire Rating US	Pass
REACH Compliant	Reach compliant (Registration, Evaluation, Authorization and Restriction of Chemicals).
Anti-Fatigue Rating	Better
Slip Resistance Rating	Better
Wear Resistance Rating	Better

Product Options

Dimensions:	28in x 31in
	36in x 31in
Variant:	Center
	End
	Single